


IWTG-NYC and IWTG-HTX

Installation Instructions

Note: Prior to using the IWTG-Gas Test Gauge please read the installation instruction in their entirety and observe warnings and cautions.

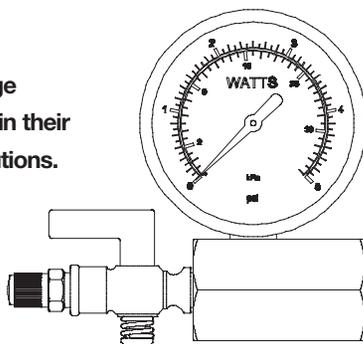

The IWTG-Gas Test Gauge is intended to accurately measure low pressures and detect the presence of leaks in natural gas and liquefied petroleum piping.

The gauge is assembled to a 3/4" (8mm) female NPT manifold. It is supplied with an air valve and a shutoff valve.

Warning: Do not use pipe dope on the threads of the valve or manifold. Use of pipe dope will void the warranty.

Installation to piping must be accomplished with Teflon tape only. Do not use pipe dope. After installation of the IWTG-Gas pressurize the system per the applicable local requirements.

Warning: Do not exceed the maximum pressure indicated on the gauge dial. Damage due to over pressurization will void the warranty. The gas/air used to pressurize the system must be dry and free of contaminants. On completion of inspection and test, discharge air from the system using the air valve.

Caution: This precision instrument must be handled and stored with care.

Model IWTG-NYC

0 – 10psi (0.7 bar) ± 2% accuracy
2 1/2" (65mm) dial face

Model IWTG-NYC

0 – 5psi (0.3 bar) ± 2% accuracy
2 1/2" (65mm) dial face

Model IWTG-HTX

0 – 10psi (0.7 bar) ± 1% accuracy
4" (100mm) dial face with indicator hand

Model IWTG-HTX

0 – 5psi (0.3 bar) ± 1% accuracy
4" (100mm) dial face with indicator hand

CALIFORNIA PROPOSITION 65 WARNING

WARNING: This product contains chemicals known to the State of California to cause cancer and birth defects or other reproductive harm. (California law requires this warning to be given to customers in the State of California.)

For more information: www.watts.com/prop65

Limited Warranty: Watts Regulator Co. (the "Company") warrants each product to be free from defects in material and workmanship under normal usage for a period of one year from the date of original shipment. In the event of such defects within the warranty period, the Company will, at its option, replace or recondition the product without charge.

THE WARRANTY SET FORTH HEREIN IS GIVEN EXPRESSLY AND IS THE ONLY WARRANTY GIVEN BY THE COMPANY WITH RESPECT TO THE PRODUCT. THE COMPANY MAKES NO OTHER WARRANTIES, EXPRESS OR IMPLIED. THE COMPANY HEREBY SPECIFICALLY DISCLAIMS ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING BUT NOT LIMITED TO THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE.

The remedy described in the first paragraph of this warranty shall constitute the sole and exclusive remedy for breach of warranty, and the Company shall not be responsible for any incidental, special or consequential damages, including without limitation, lost profits or the cost of repairing or replacing other property which is damaged if this product does not work properly, other costs resulting from labor charges, delays, vandalism, negligence, fouling caused by foreign material, damage from adverse water conditions, chemical, or any other circumstances over which the Company has no control. This warranty shall be invalidated by any abuse, misuse, misapplication, improper installation or improper maintenance or alteration of the product.

Some States do not allow limitations on how long an implied warranty lasts, and some States do not allow the exclusion or limitation of incidental or consequential damages. Therefore the above limitations may not apply to you. This Limited Warranty gives you specific legal rights, and you may have other rights that vary from State to State. You should consult applicable state laws to determine your rights. **SO FAR AS IS CONSISTENT WITH APPLICABLE STATE LAW, ANY IMPLIED WARRANTIES THAT MAY NOT BE DISCLAIMED, INCLUDING THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE, ARE LIMITED IN DURATION TO ONE YEAR FROM THE DATE OF ORIGINAL SHIPMENT.**

WATTS®

**ISO 9001-2000
CERTIFIED**



Water Safety & Flow Control Products

USA: 815 Chestnut St., No. Andover, MA 01845-6098; www.watts.com

Canada: 5435 North Service Rd., Burlington, ONT. L7L 5H7; www.wattscanada.ca

WTG-NYC and WTG-HTX

Installation Instructions

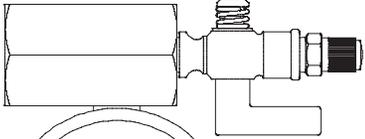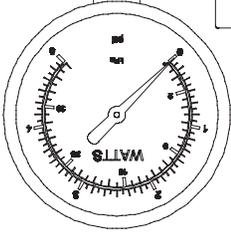

The WTG-Gas Test Gauge is intended to accurately measure low pressures and detect the presence of leaks in natural gas and liquefied petroleum piping. The gauge is assembled to a 3/4" (8mm) female NPT manifold. It is supplied with an air valve and a shut-off valve.

Warning: Do not use pipe dope on the threads of the valve or manifold. Use of pipe dope will void the warranty.

Installation to piping must be accomplished with Teflon tape only. Do not use pipe dope. After installation of the WTG-Gas pressurize the system per the applicable local requirements.

Warning: Do not exceed the maximum pressure indicated on the gauge dial. Damage due to over pressurization will void the warranty. The gas/air used to pressurize the system must be dry and free of contaminants. On completion of inspection and test, discharge air from the system using the air valve.

Caution: This precision instrument must be handled and stored with care.

Model IWTG-NYC

0 – 10psi (0.7 bar) ± 2% accuracy
2 1/2" (65mm) dial face

Model IWTG-NYC

0 – 5psi (0.3 bar) ± 2% accuracy
2 1/2" (65mm) dial face

Model IWTG-HTX

0 – 10psi (0.7 bar) ± 1% accuracy
4" (100mm) dial face with indicator hand

Model IWTG-HTX

0 – 5psi (0.3 bar) ± 1% accuracy
4" (100mm) dial face with indicator hand



Water Safety & Flow Control Products

USA: 815 Chestnut St., No. Andover, MA 01845-6098; www.watts.com

Canada: 5435 North Service Rd., Burlington, ONT. L7L 5H7; www.wattscanada.ca

IS-WTG-GAS-HTX/NYC 0845

EDP# 1915922

© Watts, 2008

Limited Warranty: Watts Regulator Co. (the "Company") warrants each product to be free from defects in material and workmanship under normal usage for a period of one year from the date of original shipment. In the event of such defects within the warranty period, the Company will, at its option, replace or recondition the product without charge. **THE WARRANTY SET FORTH HEREIN IS GIVEN EXPRESSLY AND IS THE ONLY WARRANTY GIVEN BY THE COMPANY WITH RESPECT TO THE PRODUCT. THE COMPANY MAKES NO OTHER WARRANTIES, EXPRESS OR IMPLIED. THE COMPANY HEREBY SPECIFICALLY DISCLAIMS ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING BUT NOT LIMITED TO THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE.** The remedy described in the first paragraph of this warranty shall constitute the sole and exclusive remedy for breach of warranty, and the Company shall not be responsible for any incidental, special or consequential damages, including without limitation, lost profits or the cost of repairing or replacing other property which is damaged if this product does not work properly, other costs resulting from labor charges, delays, vandalism, negligence, fouling caused by foreign material, damage from adverse water conditions, chemical, or any other circumstances over which the Company has no control. This warranty shall be invalidated by any abuse, misuse, misapplication, improper installation or improper maintenance or alteration of the product. Some States do not allow an implied warranty lasts, and some States do not allow the exclusion or limitation of incidental or consequential damages. Therefore the above limitations may not apply to you. This Limited Warranty gives you specific legal rights, and you may have other rights that vary from State to State. You should consult applicable state laws to determine your rights. **SO FAR AS IS CONSISTENT WITH APPLICABLE STATE LAW, ANY IMPLIED WARRANTIES THAT MAY NOT BE DISCLAIMED, INCLUDING THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE, ARE LIMITED IN DURATION TO ONE YEAR FROM THE DATE OF ORIGINAL SHIPMENT.**

CALIFORNIA PROPOSITION 65 WARNING
WARNING: This product contains chemicals known to the State of California to cause cancer and birth defects or other reproductive harm. (California law requires this warning to be given to customers in the State of California.)
 For more information: www.watts.com/prop65