


# Series FH-1-M1-PEX

1/2" PEX Inlet x 3/4" Hose

Freezeless, Self Draining Wall Hydrants,  
PEX End Connection

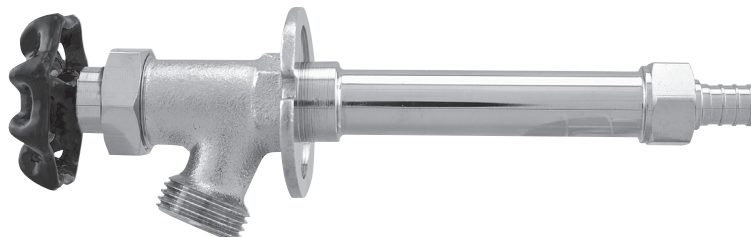

FH-1-MI-PEX

## Installation Instructions

### INSTALLERS PLEASE NOTE:

- Hose** end must be installed sufficiently lower than seat end to allow for proper drainage.
- Follow PEX tubing manufacturer's crimp joining instructions. Watts PEX end freezeless wall hydrants conform to ASTM F1807-04 PEX end specifications.

Crimp outside diameters should fall within these dimensions when measured with a micrometer or caliper.

RING SIZE	MINIMUM	MAXIMUM
1/2"	0.700"	0.715"

**NOTE:** The frost-proof sill cock assures no-freeze operation because the valve mechanism shuts off water inside the building where it is heated. If building will be unheated for any length of time, then all water lines should be drained and plumbing fixtures winterized.

Please provide this instruction sheet to the end user.

A plastic siding wedge is provided to compensate for lap siding installations. Slip the wedge between frost-proof flange and siding to form an attractive finish and solid base for mounting.

Secure sill cock flange with two #8 or #10 oval-head wood screws (of proper length) or with appropriate masonry hardware.



SIDING  
WEDGE

### To Service:

Close supply pressure to frost proof sill cock flange. Remove handle and bonnet, slide stem out. Replace all rubber parts and disc screw. Reinsert stem, bonnet and handle.

### Series FH-1-M1, FH-2-M1, and FH-1-M1-PEX

Ordering Code No.	Kit No.	Valve Series	Size
0723126	FH-M1-RK	FH-M1	All

Kit consists of: Check sub-assembly, Check spring and Stem packing.

### CALIFORNIA PROPOSITION 65 WARNING

**WARNING:** This product contains chemicals known to the State of California to cause cancer and birth defects or other reproductive harm. (California law requires this warning to be given to customers in the State of California.)

For more information: [www.watts.com/prop65](http://www.watts.com/prop65)

**Limited Warranty:** Watts Regulator Co. (the "Company") warrants each product to be free from defects in material and workmanship under normal usage for a period of one year from the date of original shipment. In the event of such defects within the warranty period, the Company will, at its option, replace or recondition the product without charge.

**THE WARRANTY SET FORTH HEREIN IS GIVEN EXPRESSLY AND IS THE ONLY WARRANTY GIVEN BY THE COMPANY WITH RESPECT TO THE PRODUCT. THE COMPANY MAKES NO OTHER WARRANTIES, EXPRESS OR IMPLIED. THE COMPANY HEREBY SPECIFICALLY DISCLAIMS ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING BUT NOT LIMITED TO THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE.**

The remedy described in the first paragraph of this warranty shall constitute the sole and exclusive remedy for breach of warranty, and the Company shall not be responsible for any incidental, special or consequential damages, including without limitation, lost profits or the cost of repairing or replacing other property which is damaged if this product does not work properly, other costs resulting from labor charges, delays, vandalism, negligence, fouling caused by foreign material, damage from adverse water conditions, chemical, or any other circumstances over which the Company has no control. This warranty shall be invalidated by any abuse, misuse, misapplication, improper installation or improper maintenance or alteration of the product.

Some States do not allow limitations on how long an implied warranty lasts, and some States do not allow the exclusion or limitation of incidental or consequential damages. Therefore the above limitations may not apply to you. This Limited Warranty gives you specific legal rights, and you may have other rights that vary from State to State. You should consult applicable state laws to determine your rights. **SO FAR AS IS CONSISTENT WITH APPLICABLE STATE LAW, ANY IMPLIED WARRANTIES THAT MAY NOT BE DISCLAIMED, INCLUDING THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE, ARE LIMITED IN DURATION TO ONE YEAR FROM THE DATE OF ORIGINAL SHIPMENT.**

# WATTS®

Water Safety & Flow Control Products

ISO 9001-2000  
CERTIFIED

USA: 815 Chestnut St., No. Andover, MA 01845-6098; [www.watts.com](http://www.watts.com)

Canada: 5435 North Service Rd., Burlington, ONT. L7L 5H7; [www.wattscanada.ca](http://www.wattscanada.ca)