

Engineering Specification

Job Name _____

Contractor _____

Job Location _____

Approval _____

Engineer _____

Contractor's P.O. No. _____

Approval _____

Representative _____

HY-330

Moderate Climate Wall Hydrant with NB Box and Integral Vacuum Breaker


Specification

Watts HY-330 concealed moderate climate key operated wall hydrant with nickel bronze box and door, chrome plated hydrant face, integral vacuum breaker, 3/4" hose connection, 3/4" female x 1" male pipe connection, all bronze head, seat casting and internal working parts, and loose key. Complies with ASSE 1019-2004, UPC/IAPMO Listed. Max. operating pressure 125 psi.

Call customer service if you need assistance with technical details.

Suffix	Options Description
-K	Cylinder Lock
-3	Stainless Steel Box
-CIA	Complete Internal Assembly (Repair Kit)
-R	Round Stainless Steel Box

Recommended Wall Opening:
5 1/4" x 6 1/4" (133 x 158)

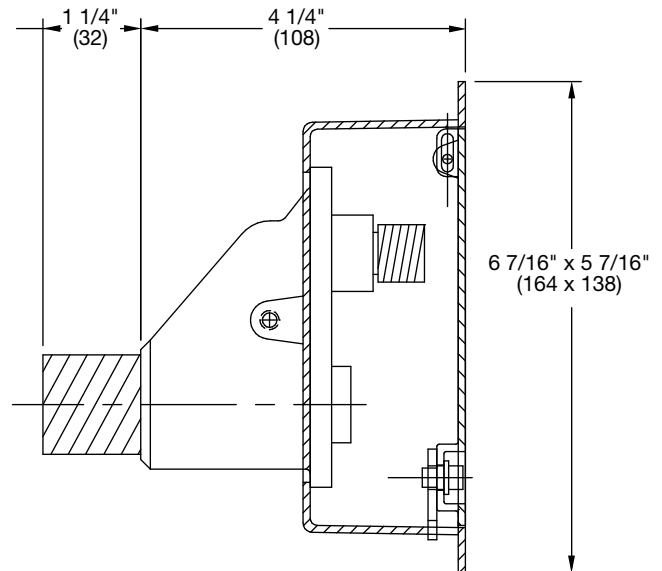

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



USA: T: (800) 338-2581 • Watts.com

Canada: T: (888) 208-8927 • Watts.ca

Latin America: T: (52) 55-4122-0138 • Watts.com

