


**FD20-R**

Tag: _____

**On-Grade Cast Iron
Adjustable Floor Drain
w/Round Strainer****PROLINE**

SPECIFICATION: Watts ProLine FD20-R On-Grade cast iron floor drain with adjustable round nickel bronze, ductile iron, or stainless steel strainer.

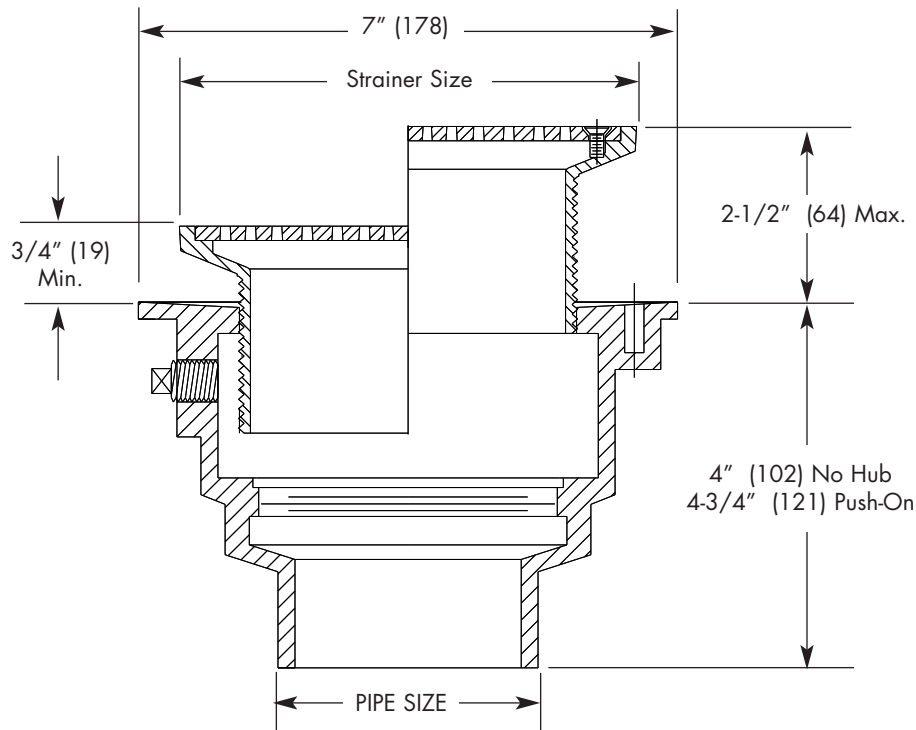

Pipe Sizing (Select One)		
Suffix	Description	
-2NH	2" No Hub	☐
-2PT	2" Push-On	☐
-3NH	3" No Hub	☐
-3PT	3" Push-On	☐
-4NH	4" No Hub	☐
-4PT	4" Push-On	☐

Strainers (Select One)		
Suffix	Description	
-5R	5" Round Nickel Bronze	☐
-5RDI	5" Round Ductile Iron	☐
-5RSS	5" Round Stainless Steel	☐
-6R	6" Round Nickel Bronze	☐
-6RSS	6" Round Stainless Steel	☐

Options (Select One or More)		
Suffix	Description	
-B	Sediment Bucket	☐
-BV	Backwater Valve	☐
-E	Strainer Extension	☐
-G	CI Round Funnel	☐
-GNB	NB Round Funnel	☐
-H	CI Oval Funnel	☐
-HNB	NB Oval Funnel	☐
-TPT	Trap Primer Tapping	☐
-VP	Vandal Proof Screws	☐

Job Name _____ Contractor _____

Job Location _____ Contractor's P.O. No. _____

Engineer _____ Representative _____

WATTS Drainage reserves the right to modify or change product design or construction without prior notice and without incurring any obligation to make similar changes and modifications to products previously or subsequently sold. See your WATTS Drainage representative for any clarification. Dimensions are subject to manufacturing tolerances.

**Specification Drainage Products**USA: 100 Watts Road, Spindale, NC, 28160-2298; TEL: 828-288-2179 TOLL-FREE: 1-800-338-2581 www.watts.com