


**FS55**

Tag: _____

**Porcelain Enameled
Cast Iron Floor Sink****PROLINE**

SPECIFICATION: Watts ProLine FS55 12" (305) square x 6" (152) deep white porcelain enamel coated cast iron floor sink with loose set grate, and aluminum dome bottom strainer.

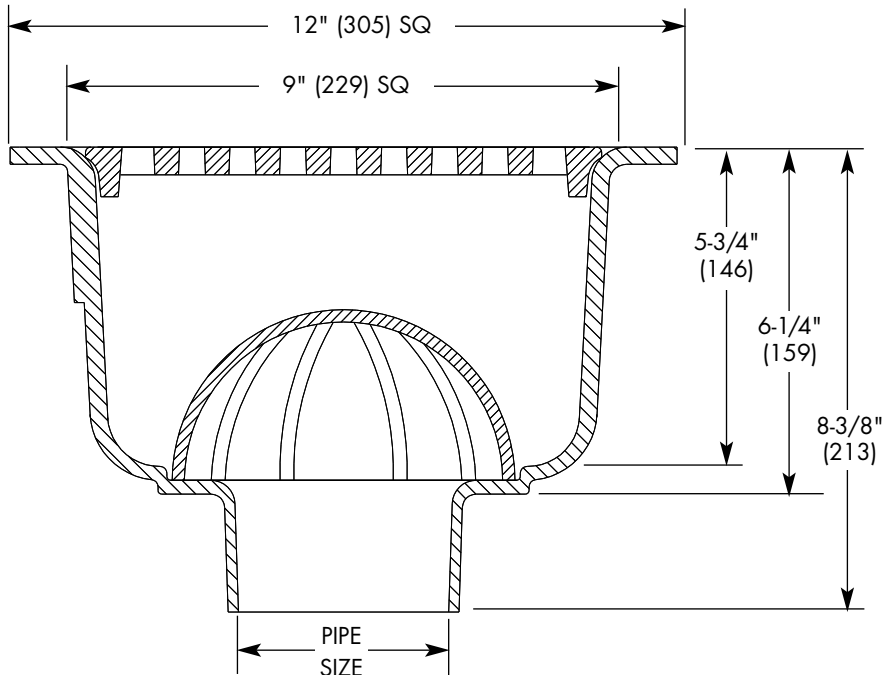

Pipe Sizing (Select One)		
Suffix	Description	
-2NH	2" No Hub	<input type="checkbox"/>
-2PT	2" Push-On	<input type="checkbox"/>
-3NH	3" No Hub	<input type="checkbox"/>
-3PT	3" Push-On	<input type="checkbox"/>
-4NH	4" No Hub	<input type="checkbox"/>
-4PT	4" Push-On	<input type="checkbox"/>

Options (Select One or More)		
Suffix	Description	
-2G	1/2 Grate	<input type="checkbox"/>
-3G	3/4 Grate	<input type="checkbox"/>
-B	Sediment Bucket	<input type="checkbox"/>
-G	CI Round Funnel	<input type="checkbox"/>
-GNB	NB Round Funnel	<input type="checkbox"/>
-H	CI Oval Funnel	<input type="checkbox"/>
-HNB	NB Oval Funnel	<input type="checkbox"/>
-LG	Less Grate	<input type="checkbox"/>
-NB	Nickel Bronze Top	<input type="checkbox"/>
-VP	Vandal Proof Screws (w/-NB Only)	<input type="checkbox"/>

Job Name _____

Contractor _____

Job Location _____

Contractor's P.O. No. _____

Engineer _____

Representative _____

WATTS Drainage reserves the right to modify or change product design or construction without prior notice and without incurring any obligation to make similar changes and modifications to products previously or subsequently sold. See your WATTS Drainage representative for any clarification. Dimensions are subject to manufacturing tolerances.



© Watts Drainage 2004

USA: 100 Watts Road, Spindale, NC, 28160 TEL: 828-288-2179 TOLL-FREE: 1-800-338-2581 Website: www.wattsdrainage.com