



GP Series

Tag: _____


**PDI Certified
Grease Interceptor**

PROLINE

SPECIFICATION: Watts ProLine GP Series PDI Certified recessed or floor mounted epoxy coated steel grease interceptor with external flow control fitting and no hub connections.



Options		
-E	Extension	☐
-THD	Threaded Connections	☐

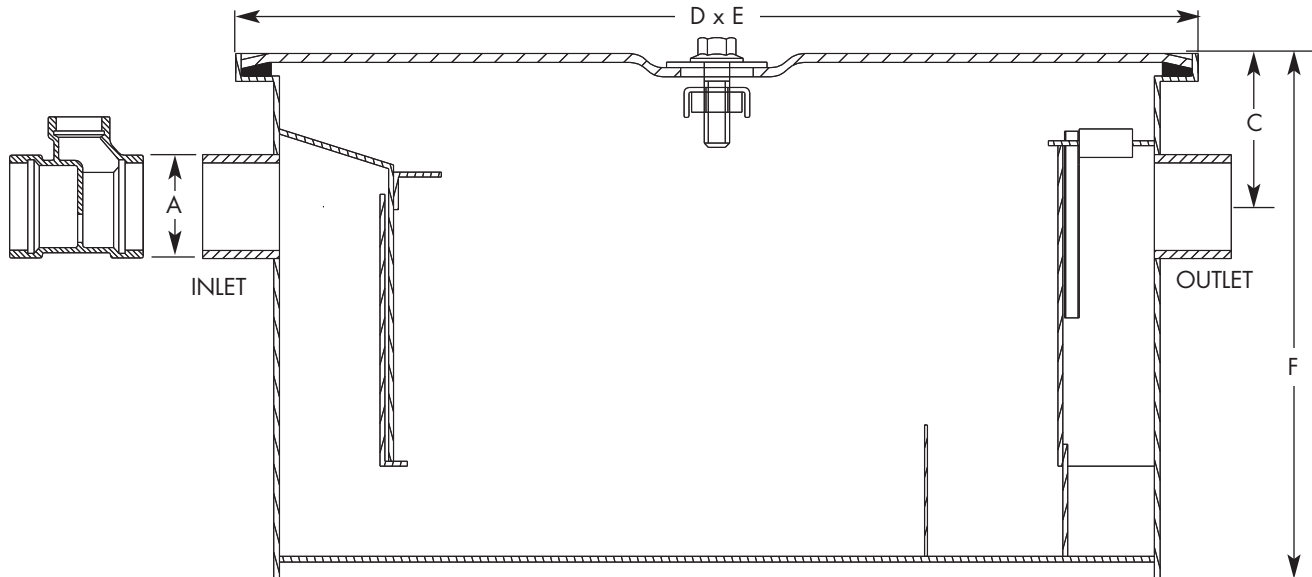

Model	Flow Rate		Capacity		Pipe Size A		C		Length D		Width E		Height F	
	GPM	LPM	Lbs.	kg.	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm
GP-4	4	15	8	3.6	2	50	3-1/4	83	16	406	10	254	11	279
GP-7	7	27	14	6.4	2	50	3-1/2	89	18	457	13	330	12	305
GP-10	10	38	20	9.0	2	50	3-1/2	89	21-3/4	552	14	356	12	305
GP-15	15	57	30	13.6	2	50	3-1/2	89	22	559	15	381	14	356
GP-20	20	76	40	18.0	3	76	3-1/2	89	24	610	15-3/4	400	15	381
GP-25	25	95	50	22.6	3	76	4-1/2	114	26	660	16-1/2	419	16-1/2	419
GP-35	35	133	70	31.8	3	76	5	127	30	762	18	457	19	483
GP-50	50	190	100	45.4	4	100	5-1/2	140	32	813	22	559	21-1/2	546

Job Name _____ Contractor _____

Job Location _____ Contractor's P.O. No. _____

Engineer _____ Representative _____

WATTS Drainage reserves the right to modify or change product design or construction without prior notice and without incurring any obligation to make similar changes and modifications to products previously or subsequently sold. See your WATTS Drainage representative for any clarification. Dimensions are subject to manufacturing tolerances.



© Watts Drainage 2004

USA: 100 Watts Road, Spindale, NC, 28160 TEL: 828-288-2179 TOLL-FREE: 1-800-338-2581 Website: www.wattsdrainage.com