


**RD1****10" Dia. Roof Drain**

Tag: _____

PROLINE

SPECIFICATION: Watts ProLine RD1 PVC, ABS, or cast iron roof drain with aluminum alloy flashing clamp, and secured poly or cast iron dome.

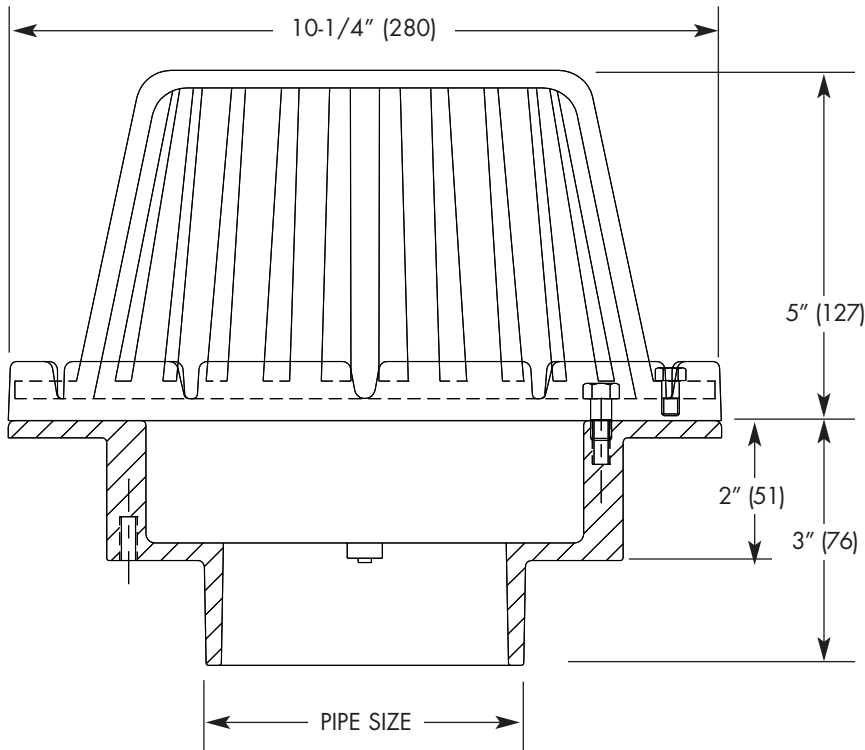

Pipe Sizing (Select One)		
Suffix	Description	
-2PVC	2" PVC	☐
-2ABS	2" ABS	☐
-2NH	2" No Hub	☐
-3PVC	3" PVC	☐
-3ABS	3" ABS	☐
-3NH	3" No Hub	☐
-4PVC	4" PVC	☐
-4ABS	4" ABS	☐
-4NH	4" No Hub	☐

Options (Select One or More)		
Suffix	Description	
-D	Deck Clamp	☐
-E	Adjustable Extension	☐
-GG	SS Gravel Guard	☐
-M	Cast Iron Dome	☐
-P	Sump Receiver	☐
-R	2" External Overflow Dam	☐
-VP	Vandal Proof Screws	☐
-X	Flotrol Device	☐
2DP	Poly Dome Only	☐
2D	Cast Iron Dome Only	☐

Job Name _____ Contractor _____

Job Location _____ Contractor's P.O. No. _____

Engineer _____ Representative _____

WATTS Drainage reserves the right to modify or change product design or construction without prior notice and without incurring any obligation to make similar changes and modifications to products previously or subsequently sold. See your WATTS Drainage representative for any clarification. Dimensions are subject to manufacturing tolerances.

**Specification Drainage Products**USA: 100 Watts Road, Spindale, NC, 28160-2298; TEL: 828-288-2179 TOLL-FREE: 1-800-338-2581 www.watts.com