

For Commercial Applications

Job Name _____ Contractor _____

Job Location _____ Approval _____

Engineer _____ Contractor's P.O. No. _____

Approval _____ Representative _____

Tag _____


OI-K Large Capacity Oil Interceptor Specification

Watts OI-K Series recessed or floor mounted epoxy coated steel oil interceptor with gasketed epoxy coated steel skid-proof cover secured with hex head center bolt(s), double wall deep seal trap, draw-off connection and dual vent connections, integral stainless steel flow control plate, and no hub (standard) connections.

Flow Rate (Select One)	Size	Description	□
75	75 GPM		<input type="checkbox"/>
100	100 GPM		<input type="checkbox"/>
150	150 GPM		<input type="checkbox"/>
200	200 GPM		<input type="checkbox"/>
250	250 GPM		<input type="checkbox"/>
300	300 GPM		<input type="checkbox"/>
400	400 GPM		<input type="checkbox"/>
500	500 GPM		<input type="checkbox"/>

Options (Select One or More)	Size	Description	□
-B		Sediment Bucket	<input type="checkbox"/>
-E		Extension	<input type="checkbox"/>
-FC		Flange & Clamp Device	<input type="checkbox"/>
-HD		Heavy Duty (10,000 lb.) Traffic Cover*	<input type="checkbox"/>
-O		Inlet & Outlet other than Standard Size	<input type="checkbox"/>
-SS		Stainless Steel	<input type="checkbox"/>
-THD		Threaded Connections	<input type="checkbox"/>

* HD Option Requires Minimum 3" Ext.

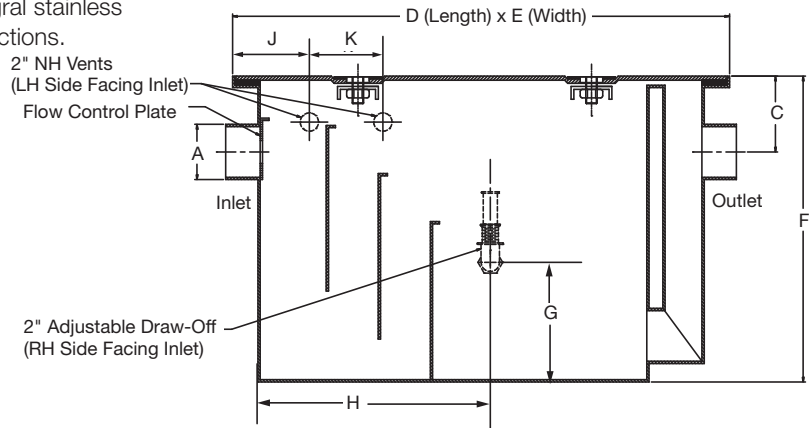

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Interceptor	Flow	A	C	D	E	F	G	H	J	K
Catalog	Rate	Inlet &	Top to				Base to			
Number	GPM	Outlet	Center	Length	Width	Height	Center			
OI-75-K	75	4"(102)	4 1/2"(114)	39 3/4"(1010)	30 3/4"(781)	23"(584)	9 1/2"(241)	21 3/4"(552)	8"(203)	7"(178)
OI-100-K	100	4"(102)	4 1/2"(114)	39 3/4"(1010)	30 3/4"(781)	33"(838)	19 1/2"(495)	21 3/4"(552)	8"(203)	7"(178)
OI-150-K	150	4"(102)	4 1/2"(114)	39 3/4"(1010)	30 3/4"(781)	43"(1092)	29 1/2"(749)	21 3/4"(552)	8"(203)	7"(178)
OI-200-K	200	4"(102)	6 1/2"(165)	52"(1321)	34"(864)	34"(864)	18 1/2"(470)	41"(1041)	8"(203)	7"(178)
OI-250-K	250	4"(102)	6 1/2"(165)	52"(1321)	34"(864)	46"(1168)	30 1/2"(775)	45"(1143)	8"(203)	7"(178)
OI-300-K	300	6"(152)	10"(254)	76"(1930)	48"(1219)	48"(1219)	28"(711)	48"(1219)	12"(305)	10"(254)
OI-400-K	400	6"(152)	10"(254)	83"(2108)	55"(1397)	52"(1321)	32"(813)	52"(1321)	12"(305)	10"(254)
OI-500-K	500	6"(152)	10"(254)	91"(2311)	60"(1524)	63"(1600)	43"(1092)	63"(1600)	12"(305)	10"(254)

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



USA: T: (800) 338-2581 • F: (978) 975-8350 • Watts.com
Canada: T: (905) 332-4090 • F: (905) 332-7068 • Watts.ca
Latin America: T: (52) 81-1001-8600 • Watts.com