

Engineering Specification

Job Name _____

Contractor _____

Job Location _____

Approval _____

Engineer _____

Contractor's P.O. No. _____

Approval _____

Representative _____

HY-440

Moderate Climate Narrow Wall Hydrant

Specification


Watts HY-440 moderate climate anti-siphon narrow wall hydrant with chrome plated face, integral vacuum breaker, 3/4" hose connection, 360 degree swivel pipe connection with 3/4" female/1" male threads. Bronze head, seat casting, internal working parts, and loose key. Complies with ASSE 1019-2004, UPC/IAPMO Listed. Maximum operating pressure 125 psi.



Call customer service if you need assistance with technical details.

Options	
Suffix	Description
-CIA	Complete Internal Assembly (Repair Kit)

Recommended Wall Opening:
2" (51) x 3 7/8" (98)

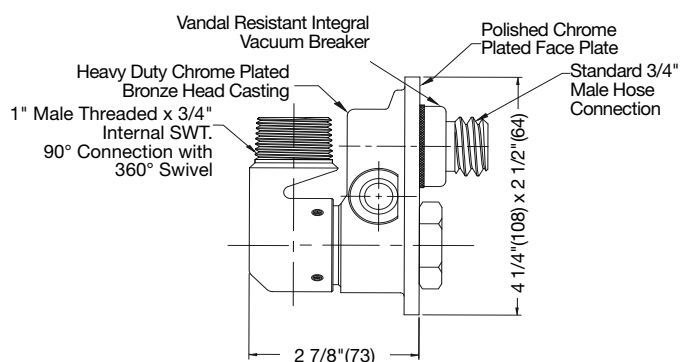

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



USA: T: (800) 338-2581 • Watts.com

Canada: T: (888) 208-8927 • Watts.ca

Latin America: T: (52) 55-4122-0138 • Watts.com

ES-WD-HY-440 2518

© 2025 Watts

