

MQ 3-45


WATTS INSTRUCTIONS





Watts.com/MQPump

Watts.com

WATTS®


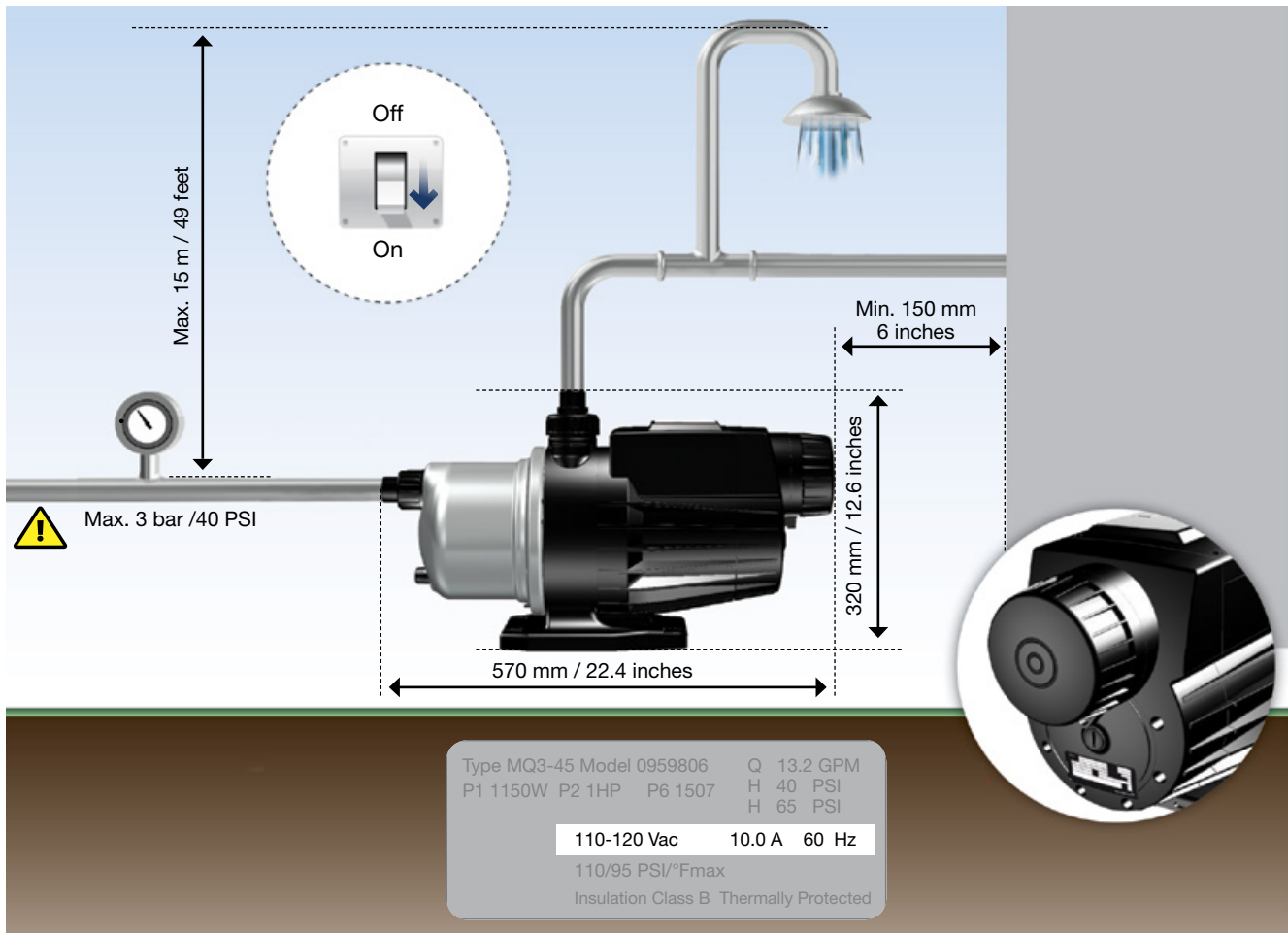


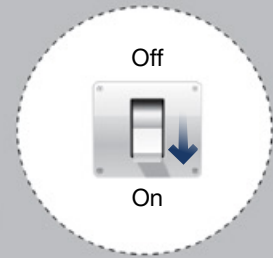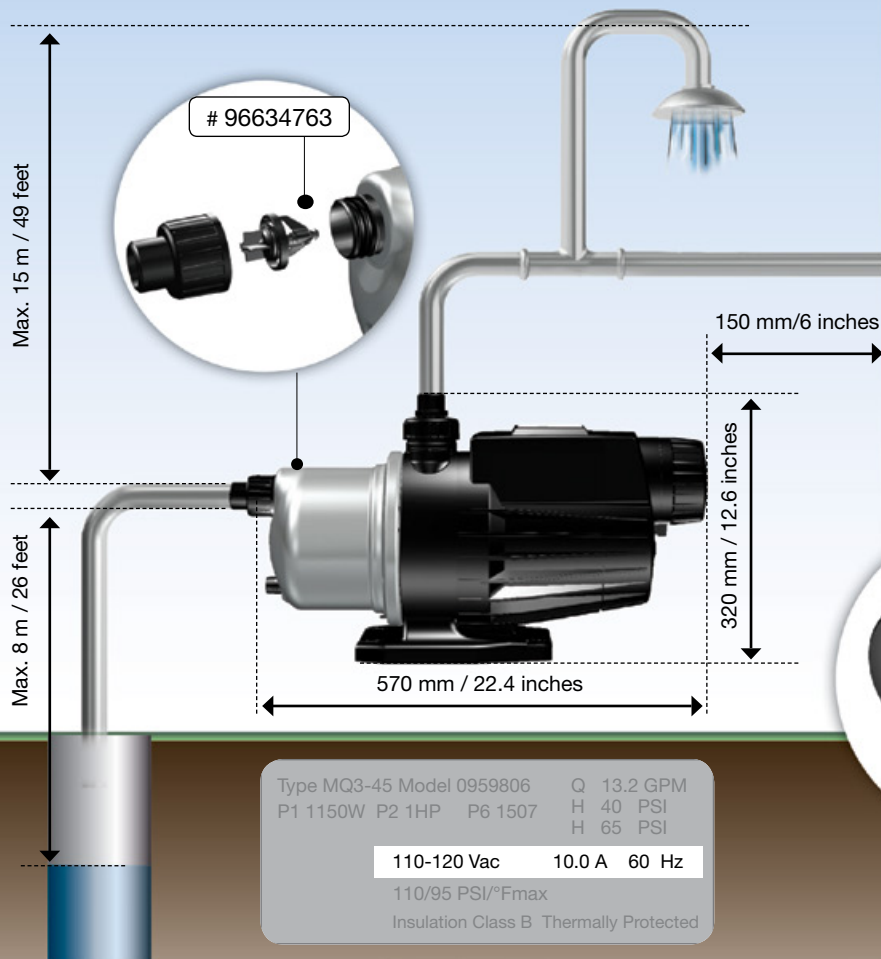




Type MQ3-45 Model 0959806 Q 13.2 GPM
P1 1150W P2 1HP P6 1507 H 40 PSI
H 65 PSI

110-120 Vac	10.0 A	60 Hz
-------------	--------	-------



110/95 PSI/°Fmax
Insulation Class B Thermally Protected

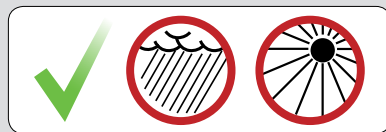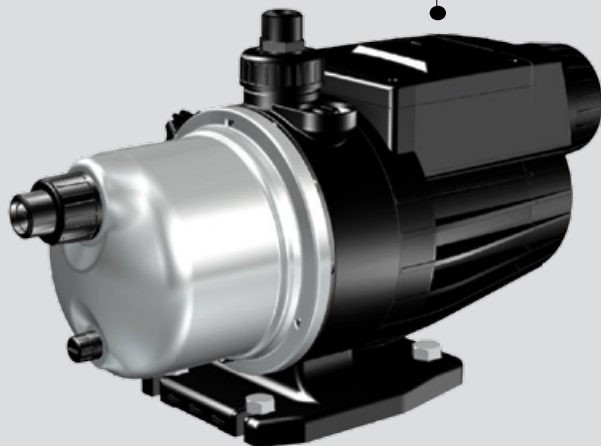

1

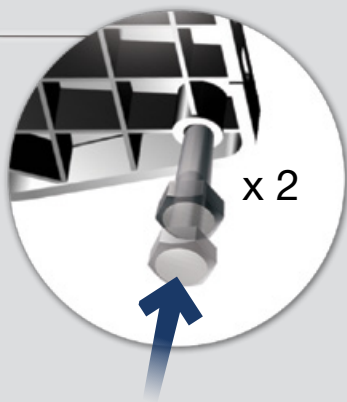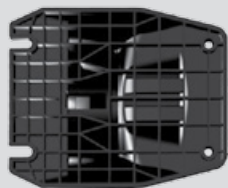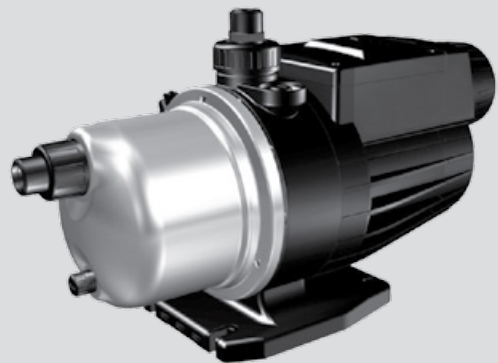



190 mm / 7.5 inches

  114 mm /
4.5 inches


Max. 18 °




2

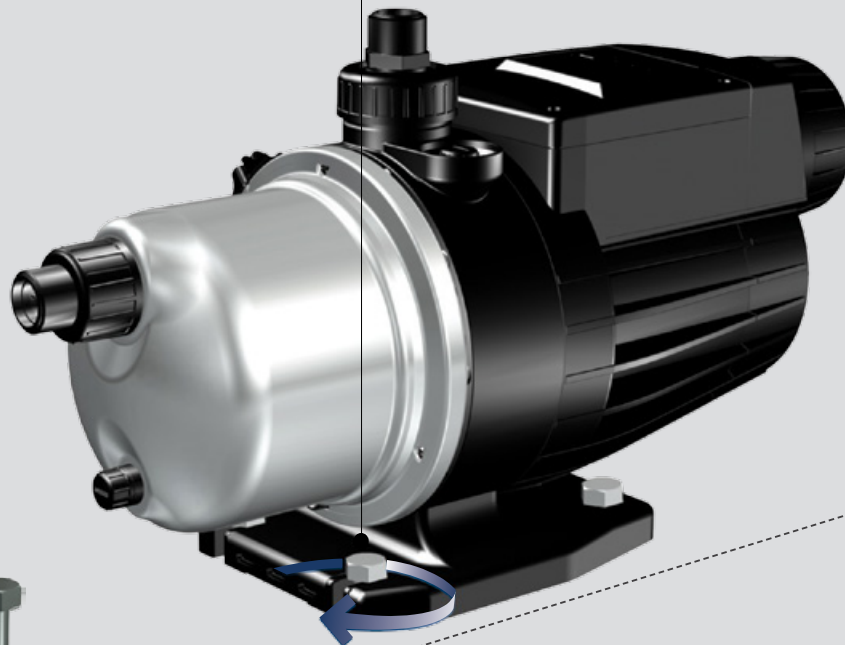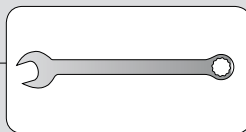


4 x

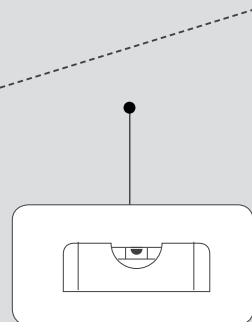


3

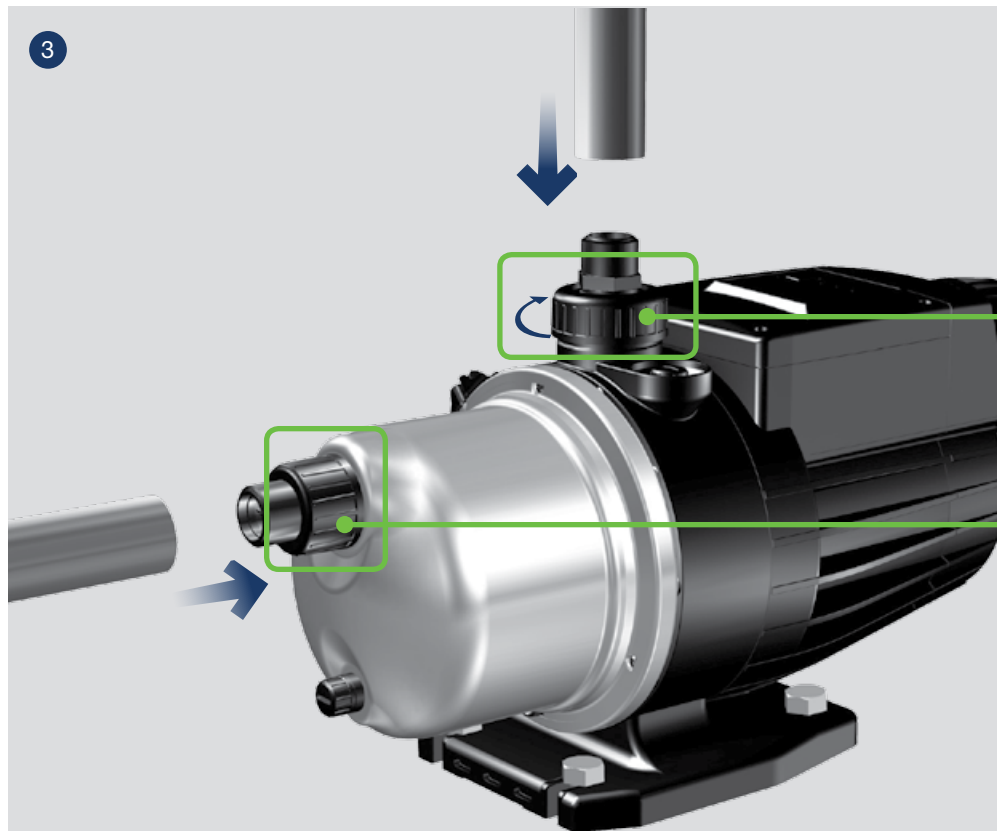





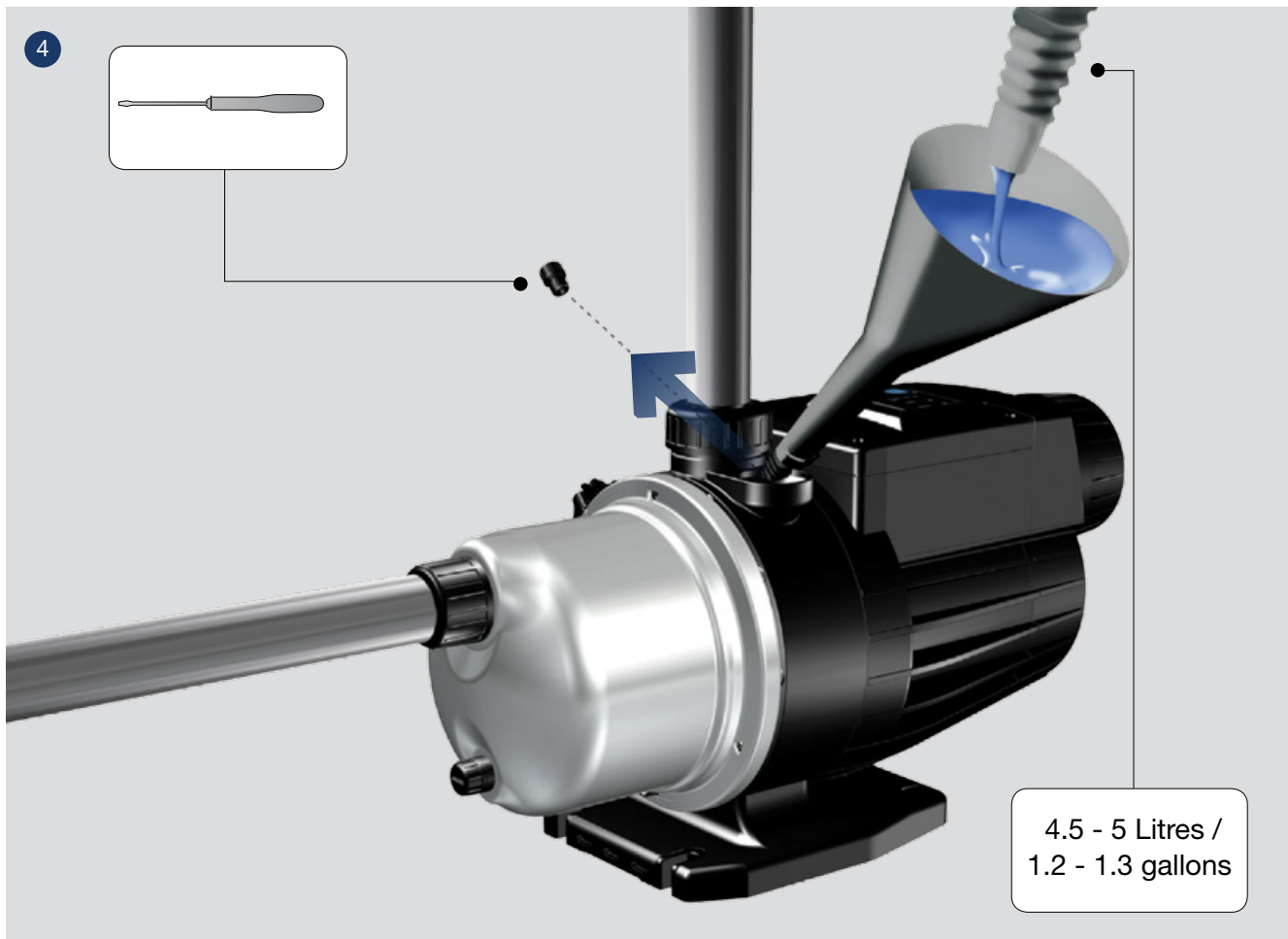


5

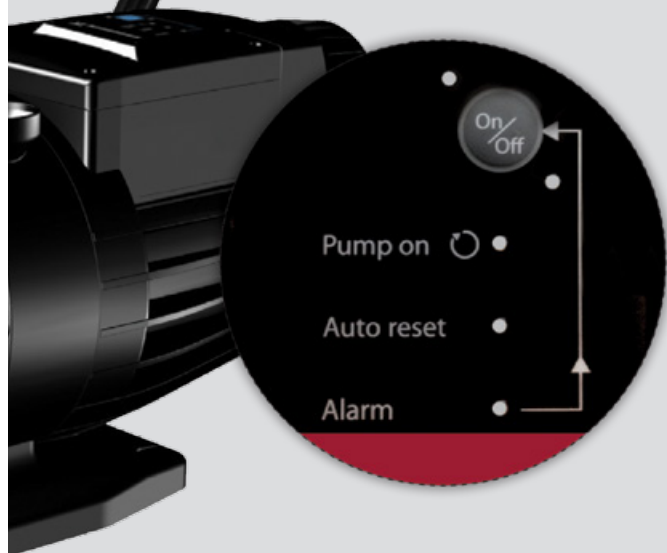

6

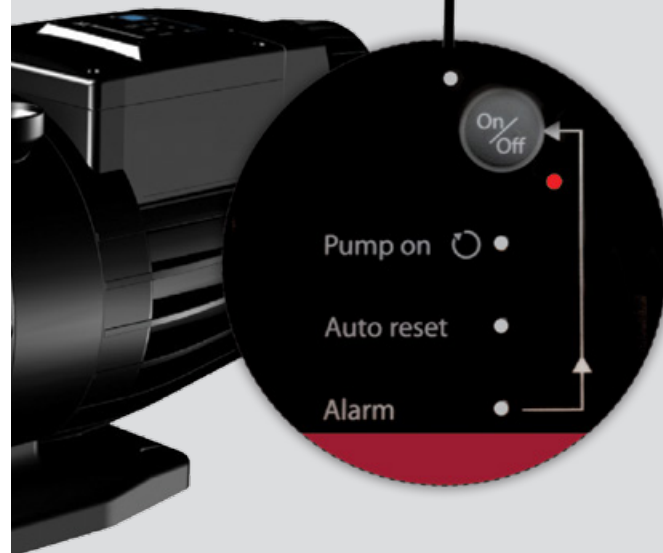

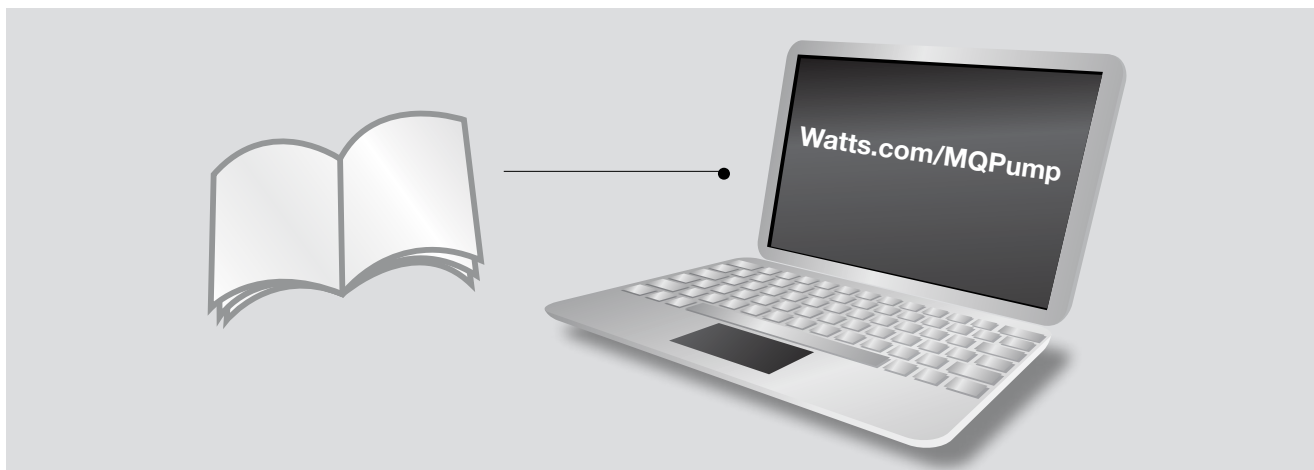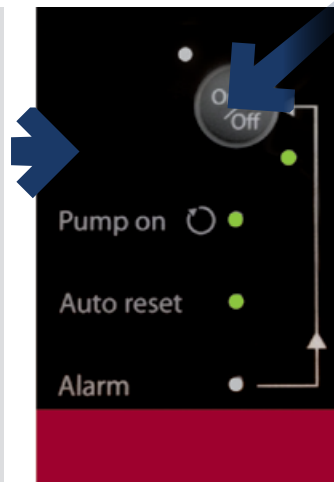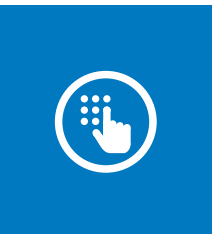 



96450698



96526663



98652420



96634763



96693071

