

Engineering Specification

Job Name _____

Contractor _____

Job Location _____

Approval _____

Engineer _____

Contractor's P.O. No. _____

Approval _____

Representative _____

RD-200-CP

Roof Drain with 8" x 8" Promenade Top

Specification

Watts RD-200-CP epoxy coated cast iron roof drain with flashing clamp, 8" x 8" square heel proof epoxy coated ductile iron promenade top, and no hub (standard) outlet.



Call customer service if you need assistance with technical details.

Pipe Sizing		
Suffix	Description	
2	2"(51) Pipe Size	☐
3	3"(76) Pipe Size	☐
4	4"(102) Pipe Size (NH Only)	☐

Outlet Type		
Suffix	Description	
NH	No Hub (MJ)	☐
P	Push On	☐
T	Threaded	☐
X	Inside Caulk	☐

Optional Body Material		
Suffix	Description	
-60	PVC Body w/Socket Outlet	☐
-61	ABS Body w/Socket Outlet	☐

Options		
Suffix	Description	
-1	All Nickel Bronze Top	☐
-5	Sediment Bucket	☐
-6	Vandal Proof	☐
-9	Hinged Grate	☐
-13	Galvanized	☐
-B	Sump Receiver	☐
-D	Underdeck Clamp (up to 4" only)	☐
-F	Deck Flange/Adj. Extension	☐
-SO	Side Outlet	☐

Load Rating	Free Area Sq. In.
HD	41

**Deck Opening 6 1/2"(165)
with Sump Receiver 8"(203)**

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

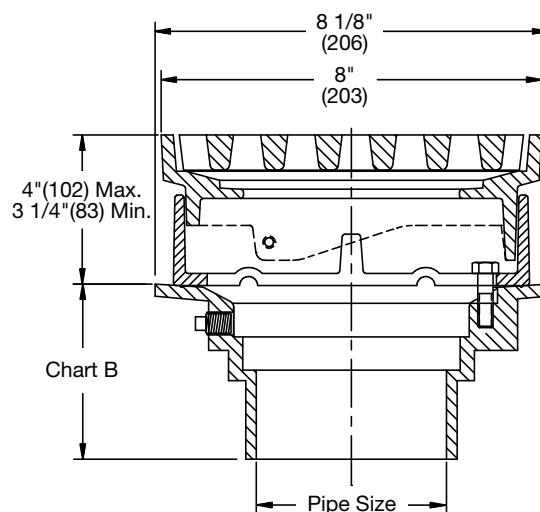


Chart B

Pipe Size	Std. No Hub	P Push On	T Female Thread	X Inside Caulk	60/61 PVC/ABS
2"(51)	3 5/8"(92)	4 1/4"(108)	4 1/4"(108)	4 1/2"(108)	4"(102)
3"(76)	3 5/8"(92)	4 1/4"(108)	4 1/4"(108)	4 1/2"(108)	4"(102)
4"(102)	3 5/8"(92)	4 1/4"(108)	4 1/4"(108)	4 1/2"(108)	4"(102)

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



USA: T: (800) 338-2581 • Watts.com

Canada: T: (888) 208-8927 • Watts.ca

Latin America: T: (52) 55-4122-0138 • Watts.com

ES-WD-RD-200-CP 2536

© 2025 Watts

