

Engineering Specification

Job Name _____

Contractor Signature _____

Orion Representative _____

Approval Date _____

Quantity Required _____

Contractor's P.O. No. _____

Please email your completed and signed submittal prior to quote or order entry to oriontanks@wattswater.com.

T11

Anti-Siphon Dilution Trap

Specification

Orion T11 POU Anti-Siphon Dilution Trap vessel will be cylindrical seamless, stress and defect free, rotationally molded construction to uniform wall thickness from virgin PE resins conforming to ASTM D 1248. Trap vessel will be 1, 2, or 5 USG capacity. Trap top assembly will be threaded and gasketed to vessel, and shall have **height adjustable top FIP inlet with dip tube and fixed side MIP outlet**.

Call customer service if you need assistance with technical details.

Select	Order No.	Description
	736500	One 1.5" FIP Top Inlet, One 1.5" MIP Side Outlet, 1 USG Sump
	736501	One 1.5" FIP Top Inlet, One 1.5" MIP Side Outlet, 2 USG Sump
	736502	One 1.5" FIP Top Inlet, One 1.5" MIP Side Outlet, 5 USG Sump

Select	Gallons	A In.	B In.	C In.	D In.	E Max.	E Min.
	1	12.25	8.25	7.5	2.88	4	12
	2	16.75	14	7.5	2.88	2.75	11
	5	19.50	16.75	11.5	2.88	2.75	11

Note: Tanks are made to ± 0.25 in. tolerance.


NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Orion product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Orion Technical Service. Orion reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Orion products previously or subsequently sold.



Note: 1 gallon pictured

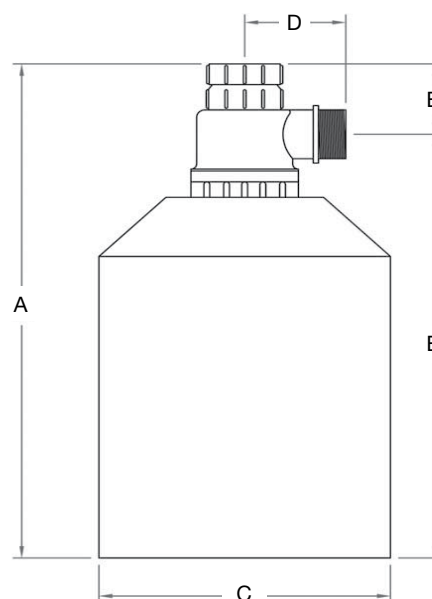

ORION®

A WATTS Brand

USA: T: (800) 334-6259 • OrionFittings.com

Canada: T: (888) 208-8927 • OrionFittings.ca

Latin America: T: (52) 55-4122-0138 • OrionFittings.com