

# Engineering Specification

Job Name \_\_\_\_\_  
 Orion Representative \_\_\_\_\_  
 Quantity Required \_\_\_\_\_

Contractor Signature \_\_\_\_\_  
 Approval Date \_\_\_\_\_  
 Contractor's P.O. No. \_\_\_\_\_

## FDSS/PPR

### Polypropylene Floor Drain with Round Stainless Steel Strainer

#### Specification

Orion FDSS/PPR adjustable combination floor drain, FRPP body with anchor flange and no hub outlet. Adjustable round medium duty stainless steel strainer available in 5", 6", and 8" sizes.



#### 5" Strainer


FRPP	SIZE (in.)	A (in.)	B (in.)	C (in.)	LOAD RATING	FREE AREA (sq. in.)
710181	2	4.50	6.13	7.38	MD	8
789561	3	4.50	6.13	7.38	MD	8
789556	4	4.50	6.13	7.38	MD	8
902276	6	4.50	6.13	7.38	MD	8

#### 6" Strainer

FRPP	SIZE (in.)	A (in.)	B (in.)	C (in.)	LOAD RATING	FREE AREA (sq. in.)
789560	2	4.50	6.13	7.38	MD	9
789563	3	4.50	6.13	7.38	MD	9
789562	4	4.50	6.13	7.38	MD	9
789565	6	4.50	6.13	7.38	MD	9

#### 8" Strainer

FRPP	SIZE (in.)	A (in.)	B (in.)	C (in.)	LOAD RATING	FREE AREA (sq. in.)
710186	2	4.50	6.65	7.65	MD	18
710268	3	4.50	6.65	7.65	MD	18
789564	4	4.50	6.65	7.65	MD	18
902207	6	4.50	6.65	7.65	MD	18

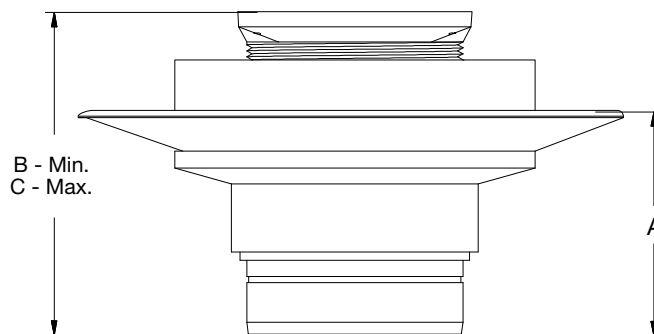

No Hub

OPTIONS	
ORDER NO.	DESCRIPTION
809163	Sediment Bucket
902145	Vandal Proof
809048	4" x 9" Oval SS Funnel

**NOTICE**

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Orion product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Orion Technical Service. Orion reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Orion products previously or subsequently sold.



**A WATTS Brand**

USA: T: (800) 334-6259 • OrionFittings.com  
 Canada: T: (888) 208-8927 • OrionFittings.ca  
 Latin America: T: (52) 55-4122-0138 • OrionFittings.com  
 ES-OR-FDSS/PPR 2607

