

Engineering Specification

Job Name _____

Contractor Signature _____

Orion Representative _____

Approval Date _____

Quantity Required _____

Contractor's P.O. No. _____

FDSS/PPR Polypropylene Floor Drain with Round Stainless Steel Strainer

Specification

Orion FDSS/PPR adjustable combination floor drain, FRPP body with anchor flange and no hub outlet. Adjustable round heavy duty stainless steel strainer and 5", 6", and 8" sizes.



5" Strainer


FRPP	Size (in.)	A	B	C
710181	2	4.50	6.13	7.38
789561	3	4.50	6.13	7.38
789556	4	4.50	6.13	7.38
902276	6	4.50	6.13	7.38

6" Strainer

FRPP	Size (in.)	A	B	C
789560	2	4.50	6.13	7.38
789563	3	4.50	6.13	7.38
789562	4	4.50	6.13	7.38
789565	6	4.50	6.13	7.38

8" Strainer

FRPP	Size (in.)	A	B	C
710186	2	4.50	6.65	7.65
710268	3	4.50	6.65	7.65
789564	4	4.50	6.65	7.65
902207	6	4.50	6.65	7.65

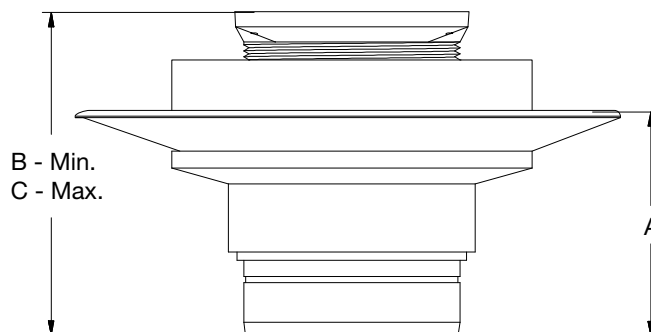

No Hub

EDP	Options
809163	Sediment Bucket

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Orion product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Orion Technical Service. Orion reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Orion products previously or subsequently sold.



A WATTS Brand