

Rainwater Harvesting - Storage Tank

Job Name _____

Contractor _____

Job Location _____

Approval _____

Engineer _____

Contractor's P.O. No. _____

Approval _____

Representative _____

RWT-PEAGF

Above Ground Polyethylene Tanks Pre-Fabricated Connections 300 – 12,000 Gallon Capacity

Polyethylene tanks are engineered for above ground water storage for commercial rainwater harvesting applications. Tanks are manufactured in single piece construction and are available in black, green, or translucent white colors. Translucent white tanks are recommended for use as buffer tanks only.

Advantages:

- Corrosion resistant high density polyethylene construction
- Black or green colors limit sunlight penetration and inhibits algae growth
- Pre-installed connection fittings for quick onsite installation

Features

- Molded platform with either 16 IN or 24 IN access lid
- Molded graduation markings (gallons)



RWT-PEAGF

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.


WARNING

Rainwater supplied by Watts rainwater harvesting systems is not potable water and is not intended for potable water applications. Do Not Drink Water supplied from Watts rainwater systems and related equipment. Users shall determine the suitability of the product for the intended application before using.

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



Tank Layout

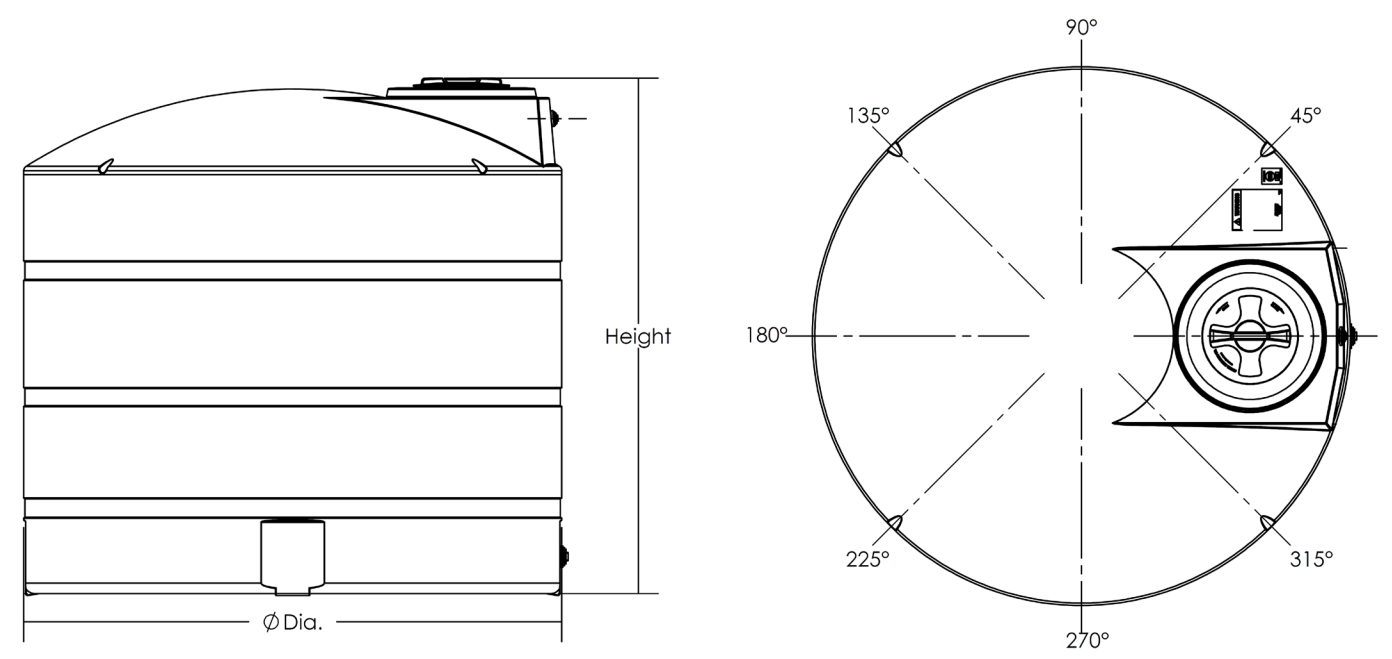

Available Models

Model	Color	Capacity	Diameter (IN)	Height (IN)	Weight
RWT-PEAGF-550W	White	550 Gallons	48	82	130
RWT-PEAGF-550B	Black	550 Gallons	48	82	130
RWT-PEAGF-550G	Green	550 Gallons	48	82	130
RWT-PEAGF-625W	White	625 Gallons	48	93	155
RWT-PEAGF-625B	Black	625 Gallons	48	93	155
RWT-PEAGF-625G	Green	625 Gallons	48	93	155
RWT-PEAGF-700W	White	700 Gallons	69	58	170
RWT-PEAGF-700B	Black	700 Gallons	69	58	170
RWT-PEAGF-700G	Green	700 Gallons	69	58	170
RWT-PEAGF-850W	White	850 Gallons	48	120	166
RWT-PEAGF-850B	Black	850 Gallons	48	120	166
RWT-PEAGF-850G	Green	850 Gallons	48	120	166
RWT-PEAGF-1000W	White	1,000 Gallons	64	84	171
RWT-PEAGF-1000B	Black	1,000 Gallons	64	84	171
RWT-PEAGF-1000G	Green	1,000 Gallons	64	84	171
RWT-PEAGF-1100W	White	1,100 Gallons	86	55	171
RWT-PEAGF-1100B	Black	1,100 Gallons	86	55	171
RWT-PEAGF-1100G	Green	1,100 Gallons	86	55	171
RWT-PEAGF-1200W	White	1,200 Gallons	64	100	203
RWT-PEAGF-1200B	Black	1,200 Gallons	64	100	203

Model	Color	Capacity	Diameter (IN)	Height (IN)	Weight
RWT-PEAGF-1500W	White	1,500 Gallons	86	74	227
RWT-PEAGF-1500B	Black	1,500 Gallons	86	74	227
RWT-PEAGF-1500G	Green	1,500 Gallons	86	74	227
RWT-PEAGF-1500NW	White	1,500 Gallons	64	121	295
RWT-PEAGF-1500NB	Black	1,500 Gallons	64	121	295
RWT-PEAGF-1500NG	Green	1,500 Gallons	64	121	295
RWT-PEAGF-1850W	White	1,850 Gallons	96	78	335
RWT-PEAGF-1850B	Black	1,850 Gallons	96	78	335
RWT-PEAGF-1850G	Green	1,850 Gallons	96	78	335
RWT-PEAGF-2000W	White	2,000 Gallons	86	100	335
RWT-PEAGF-2000B	Black	2,000 Gallons	86	100	335
RWT-PEAGF-2000G	Green	2,000 Gallons	86	100	335
RWT-PEAGF-2050W	White	2,050 Gallons	64	165	450
RWT-PEAGF-2050B	Black	2,050 Gallons	64	165	450
RWT-PEAGF-2050G	Green	2,050 Gallons	64	165	450
RWT-PEAGF-2400W	White	2,400 Gallons	96	95	412
RWT-PEAGF-2400B	Black	2,400 Gallons	96	95	412
RWT-PEAGF-2400G	Green	2,400 Gallons	96	95	412
RWT-PEAGF-2500W	White	2,500 Gallons	86	119	441
RWT-PEAGF-2500B	Black	2,500 Gallons	86	119	441
RWT-PEAGF-2500G	Green	2,500 Gallons	86	119	441
RWT-PEAGF-2900W	White	2,900 Gallons	96	111	568
RWT-PEAGF-2900W	Black	2,900 Gallons	96	111	568
RWT-PEAGF-2900W	Green	2,900 Gallons	96	111	568
RWT-PEAGF-3000W	White	3,000 Gallons	90	122	568
RWT-PEAGF-3000B	Black	3,000 Gallons	90	122	568
RWT-PEAGF-3000G	Green	3,000 Gallons	90	122	568
RWT-PEAGF-4000W	White	4,000 Gallons	90	162	782
RWT-PEAGF-4000B	Black	4,000 Gallons	90	162	782
RWT-PEAGF-4000G	Green	4,000 Gallons	90	162	782
RWT-PEAGF-4100W	White	4,100 Gallons	119	108	782
RWT-PEAGF-4100B	Black	4,100 Gallons	119	108	782
RWT-PEAGF-4100G	Green	4,100 Gallons	119	108	782
RWT-PEAGF-4200W	White	4,200 Gallons	95	152	782
RWT-PEAGF-4200B	Black	4,200 Gallons	95	152	782
RWT-PEAGF-4200G	Green	4,200 Gallons	95	152	782
RWT-PEAGF-5200W	White	5,200 Gallons	105	160	1101
RWT-PEAGF-5200B	Black	5,200 Gallons	105	160	1101
RWT-PEAGF-5200G	Green	5,200 Gallons	105	160	1101
RWT-PEAGF-5500W	White	5,500 Gallons	119	141	1215
RWT-PEAGF-5500B	Black	5,500 Gallons	119	141	1215
RWT-PEAGF-5500G	Green	5,500 Gallons	119	141	1215
RWT-PEAGF-5600W	White	5,600 Gallons	96	196	1350

Model	Color	Capacity	Diameter (IN)	Height (IN)	Weight
RWT-PEAGF-5600G	Green	5,600 Gallons	96	196	1350
RWT-PEAGF-6500W	White	6,500 Gallons	105	193	1776
RWT-PEAGF-6500W	Black	6,500 Gallons	105	193	1776
RWT-PEAGF-6500W	Green	6,500 Gallons	105	193	1776
RWT-PEAGF-6510W	White	6,510 Gallons	119	163	1575
RWT-PEAGF-6510B	Black	6,510 Gallons	119	163	1575
RWT-PEAGF-6510G	Green	6,510 Gallons	119	163	1575
RWT-PEAGF-7300W	White	7,300 Gallons	119	177	2028
RWT-PEAGF-7300B	Black	7,300 Gallons	119	177	2028
RWT-PEAGF-7300G	Green	7,300 Gallons	119	177	2028
RWT-PEAGF-8000W	White	8,000 Gallons	143	142	1989
RWT-PEAGF-8000B	Black	8,000 Gallons	143	142	1989
RWT-PEAGF-8000G	Green	8,000 Gallons	143	142	1989
RWT-PEAGF-8400W	White	8,400 Gallons	119	201	2758
RWT-PEAGF-8400B	Black	8,400 Gallons	119	201	2758
RWT-PEAGF-8400G	Green	8,400 Gallons	119	201	2758
RWT-PEAGF-10000W	White	10,000 Gallons	143	173	2700
RWT-PEAGF-10000B	Black	10,000 Gallons	143	173	2700
RWT-PEAGF-10000G	Green	10,000 Gallons	143	173	2700
RWT-PEAGF-12000W	White	12,000 Gallons	143	196	3400
RWT-PEAGF-12000B	Black	12,000 Gallons	143	196	3400

Suffixes

Inlet Connection

- I4 4 INCH FLANGE INLET CONNECTION
- I6 6 INCH FLANGE INLET CONNECTION
- I8 8 INCH FLANGE INLET CONNECTION
- I10 10 INCH FLANGE INLET CONNECTION
- I12 12 INCH FLANGE INLET CONNECTION

Overflow

- O4 4 INCH FLANGE OVERFLOW CONNECTION
- O6 6 INCH FLANGE OVERFLOW CONNECTION
- O8 8 INCH FLANGE OVERFLOW CONNECTION
- O10 10 INCH FLANGE OVERFLOW CONNECTION
- O12 12 INCH FLANGE OVERFLOW CONNECTION

Vent

- V4 4 INCH FLANGE VENT CONNECTION
- V6 6 INCH FLANGE VENT CONNECTION
- V8 8 INCH FLANGE VENT CONNECTION
- V10 10 INCH FLANGE VENT CONNECTION

Discharge

- D2 2 INCH FLANGE DISCHARGE CONNECTION
- D3 3 INCH FLANGE DISCHARGE CONNECTION
- D4 4 INCH FLANGE DISCHARGE CONNECTION

