

**SeaTech**<sup>®</sup>  is now  
A **WATTS** Brand

# AquaLock<sup>™</sup>

Push-to-Connect Plumbing Fittings



LIMITED  
**25 YEARS**  
WARRANTY



# Table of Contents

2	Terms and Conditions
3-6	Technical Information
7	Tubing for Plastic Series
8-9	Mini Series Fittings
10-15	Plastic Series Fittings and Valves
16	Plastic Series Push-to-Connect Manifold, Configuration Styles
17	Plastic Series Push-to-Connect Manifold, Assembly Elements
18	Plastic Series Push-to-Connect Manifold, Components
19	Uniflex Hose System
20	Tubing for Metric Series
21-24	Metric Series Fittings and Valves
25	Metric Series AquaLock Manifold, Configuration Styles
26	Metric Series AquaLock Manifold, Assembly Elements
27	Metric Series AquaLock Manifold, Components
28	Supercoil System



# Terms and Conditions

**FREIGHT TERMS:** All shipments are F.O.B. shipping point. Shipments from factory less than 1000 lbs. are F.O.B. factory. Factory shipments of 2500 and over within the continental U.S.A. will be prepaid and allowed when made at the lowest motor carrier transportation rate.

**TERMS OF SALE:** All sales are F.O.B. shipping point.

**PAYMENT TERMS:** The invoices are due and payable 30 days from the date of invoice.

**PURCHASE ORDER FORMS:** Orders submitted on customer's own purchase order forms will be accepted only with the express understanding that no statements, clauses, or conditions contained in said order form will be binding on the Seller if they in any way modify the Seller's own terms and conditions of sales.

**SPECIAL PRODUCTS:** Orders for special or modified products are non-cancelable. In the event that the customer cancels an order for such products, Watts shall charge the customer an amount equal to Watts' costs and expenses incurred in performing the purchase order prior to receipt of notice of cancellation.

**LIMITED WARRANTY:** A. Watts Regulator Co. ("Watts") warrants its WaterPEX® cross-linked polyethylene tubing, barbed PEX fittings, brass and plastic AquaLock™ fittings and manifolds, factory manufactured copper manifolds and AquaLock™ accessories to be free of defects in material and workmanship when used under normal usage in potable water systems, and installed in accordance with all Watts printed installation instructions. Specific warranty durations apply as follows:



1. Watts WaterPEX® cross-linked polyethylene (non-barrier PEX) pipe, brass and plastic barbed PEX fittings, and factory manufactured copper manifolds when installed as a system using Watts WaterPEX pipe, Watts brass or plastic barbed PEX fittings, and Watts factory manufactured copper manifolds for a period of twenty-five (25) years from the date of original shipment.
2. Watts WaterPEX® cross-linked polyethylene (non-barrier PEX) pipe, when installed with brass or plastic barbed PEX fittings manufactured by others that meet the applicable ASTM Standards (brass - ASTM F 1807) (plastic - ASTM F 2159) for a period of ten (10) years from the date of original shipment.
3. Watts WaterPEX® brass or plastic barbed PEX fittings and factory manufactured copper manifolds when installed with cross-linked polyethylene (non-barrier PEX) pipe manufactured by others that meet the ASTM F 876 requirements for a period of ten (10) years from the date of original shipment.
4. Brass, Plastic and Mini AquaLock™ fittings and manifolds for a period of twenty-five (25) years from the date of original shipment.
5. All other valves and accessories sold under the Watts WaterPEX or Watts AquaLock™ brand name for a period of two (2) years from the date of original shipment.

Watts's obligation will be to repair or replace, at its discretion, any of these products proven to be defective in material or workmanship when these products are covered under this limited warranty.

- B. In the event of a system malfunction or leak caused by defective Watts warranted materials (and not by incorrect installation, incorrect handling procedures or by jobsite or installation damage), a reasonable pre-approved amount will be allowed for repair materials and repair labor. In the event of a leak occurring in a factory manifold, you may contact Watts for either a free replacement manifold or any parts reasonably needed to repair such a leak (freight prepaid). Note that Watts limits its warranty to its tubing, valves and accessories, fittings and manifolds. Watts does not warrant the connection on any installation, as the integrity of the connection is subject to the workmanship of the contractor/installer. The connection is the sole responsibility of the person who installs it.
- C. In order to qualify for a warranty remedy under paragraph B, you must contact Watts in advance and receive a written authorization for this remedy from an authorized Watts representative. Repair materials, repair labor and freight expenses not authorized in writing in advance by Watts in this way will not be compensated.
- D. To qualify for the warranty described above, you must do the following:
  1. Use good construction techniques to install our materials, as specified in our current design and installation guidelines and technical notes. This must include field pressure testing our warranted materials before they are covered by concrete or otherwise made inaccessible.
  2. Install Watts WaterPEX® and Watts AquaLock™ materials according to all guidelines and manuals published by Watts.
  3. Install Watts WaterPEX® and Watts AquaLock™ products in a system that will not operate at temperatures or at pressures that exceed the rating printed on the tubing.
  4. The Watts warranted product must be installed in compliance with local building and plumbing codes.
- E. Evidence of tampering, mishandling, neglect, accidental damage, freeze damage or unauthorized repairs that cause damage to Watts's warranted products will void any warranty coverage for those particular products. All field connections are specifically excluded from the terms of this warranty.
- F. Watts provides a complete plumbing system offering so that it is possible to complete an installation with Watts products. However, it is possible that other manufacturers' tubing and/or fittings may be installed in any given installation. Providing that the tubing and/or fittings are manufactured to their applicable ASTM standards, and have been certified by a recognized third-party testing agency, the Watts product in the given installation will continue to be covered under this warranty. In the event of a system malfunction or leak that has other tubing and/or fitting manufacturers' components installed within the failed system, Watts will be responsible only for proven defects in material or workmanship in the Watts products. Products manufactured by another company should be reported to that manufacturer for its warranty response.
- G. Disclaimer of Warranty. **THE WARRANTY SET FORTH HEREIN IS GIVEN EXPRESSLY AND IS THE ONLY WARRANTY GIVEN BY WATTS WITH RESPECT TO THE PRODUCTS LISTED IN PARAGRAPH A. WATTS MAKES NO OTHER WARRANTIES, EXPRESS OR IMPLIED. WATTS HEREBY SPECIFICALLY DISCLAIMS ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING BUT NOT LIMITED TO THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE.**
- H. Limitation of Liability. The remedy described above shall constitute the sole and exclusive remedy for breach of warranty, and, apart from that remedy, Watts shall not be responsible for any incidental, special or consequential damages, including without limitation, lost profits or the cost of repairing or replacing other property which is damaged if these warranted products do not work properly, other costs resulting from labor charges, delays, vandalism, negligence, fouling caused by foreign material, damage from adverse water conditions, adverse chemical environments, or any other circumstances over which Watts has no control. This warranty shall be invalidated by any abuse, misuse, misapplication or improper installation of the product. Some states do not allow limitations on how long an implied warranty lasts, and some states do not allow the exclusion or limitation of incidental or consequential damages. Therefore the above limitations may not apply to you. This Limited Warranty gives you specific legal rights, and you may have other rights that vary from state to state. You should consult applicable state laws to determine your rights. **SO FAR AS IS CONSISTENT WITH APPLICABLE STATE LAW, ANY IMPLIED WARRANTIES THAT MAY NOT BE DISCLAIMED, INCLUDING THE IMPLIED WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE, ARE LIMITED IN DURATION TO ONE YEAR FROM THE DATE OF ORIGINAL SHIPMENT.**
- I. RETURNED GOODS: No material shall be returned without authorization. When credit is issued it will be at the price charged, or prevailing price if lower, less handling charges based on costs of reconditioning, boxing, etc. However, a minimum 25% handling charge will apply. A minimum handling charge of 20.00 is applied whenever the 25% handling deduction does not total 20.00. Products which are obsolete or made to special order are not returnable.

**NOTE:** Prices and terms are subject to change without notice and supersede all previous quotations. The right is reserved to change or modify product design or construction without prior notice and without incurring an obligation to make such changes and modifications on products previously or subsequently sold.

# Technical Information - Plastic/Metric Fittings

## Material Specifications

Body:	Polysulfone
Collet:	Nylon
O-Ring:	EPDM
Spacer:	Acetal
Tube Liner:	Polysulfone
Collet Clip:	Delrin

## Fitting Performance

AquaLock™	Max. Pres.	250psi @ 75°F	(17.25 bar @ 24°C)
Plastic/Metric	Max. Temp.	100psi @ 180°F	(6.8 bar @ 82°C)
	Min. Temp.	33°F (0.5°C)	

## Thread Torque Values

Size	Min. Torque Values	Max. Torque Values
1/2"	17.7 in - lbs.	26.5 in - lbs.
3/4"	22.7 in - lbs.	31 in - lbs.

## Approvals



**FDA:** Watts Plastic fittings are produced from FDA approved materials.



**NSF/ANSI 61-G:** Watts Plastic fitting products are tested, certified, and approved for contact with drinking water.



**NSF/ANSI 14:** Watts Plastic fitting products are tested, certified, and approved to NSF-14 standards.



**ASTM F877:** Watts Plastic fitting products are tested, certified, and approved to ASTM F877 performance standards.



**NSF-U.P. Code:** Watts Plastic fitting products are tested, certified, and approved and meet the requirements of the Uniform Plumbing Code.



**IAPMO ASSE 1061:** Watts Plastic fitting fittings are tested, certified and approved to ASSE 1061 for AquaLock™ fittings and approved to Canadian Standard CSA B137.5.

Lead free product is certified to NSF/ANSI 372 and conforms with the lead content requirements for lead free plumbing as defined by California, Vermont, Maryland, and Louisiana state laws and the U.S. Safe Drinking Water Act.

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

**Watts AquaLock™ Plastic/Metric fittings** are designed and manufactured to be trouble free for many years of service life. Plastic/Metric fitting products are designed and manufactured in polysulfone, a high performance thermal plastic material. All Plastic/Metric fitting products are approved and certified to NSF-61-G, NSF 14, CSA B137.5, ASTM F877, and to the Uniform Plumbing Code (U.P. Code) and ASSE 1061. Plastic/Metric fitting products are available in standard imperial inch sizes. The Watts AquaLock™ design allows for quick and easy connections without installation tools. Simply cut the plastic, copper or CPVC tubing and snap a Watts AquaLock™ fitting in place for a zero-leak connection.

Watts AquaLock™ Plastic/Metric fittings are designed for potable water systems. For other applications please refer to our Technical Service Department. Tubing should be supported at minimum of 36" to prevent excessive load to the connectors. Do not install tubing supports closer than 3 inches from the connector ends. We strongly recommend that new installations be thoroughly tested prior to use. Do not use with explosive gases, petroleum products, or other fuels.

## ⚠ CAUTION

The polysulfone material used in the AquaLock™ fittings can be compromised by exposure to volatile organic compounds (VOC's) and caustic chemicals. Therefore, **DO NOT** expose this product to any such chemical or foreign substance, which would include exposure to the following products: **Pipe Dopes (thread sealants)**, bug sprays, lubricants, cleaners, paints, bleaches, acids, solder fluxes, plastic piping primers and cements, oxidizing agents, alkaline solutions, thinners, fuels, oil based caulks, hydrocarbons, spray foam of foaming agents (insulation).

Watts recommends that all fittings and parts be stored in their original packaging until installation to protect the fitting internals from dirt and debris that may cause damage to the o-ring and the o-ring guide.

It is also recommended that all threaded connections be made with Teflon® tape only.

Failure to follow these instructions will void the warranty and possibly result in leaks and water damage.



## Material Specifications

Body:	Polypropylene
Collet:	Acetal
O-Ring:	EPDM
Spacer:	Acetal

## Fitting Performance

AquaLock™	Max. Pres.	150psi @ 70°F	(10.3 bar @ 20°C)
Mini	Max. Temp.	60psi @ 140°F	(4.1 bar @ 60°C)
	Min. Temp.	33°F (0.5°C)	

## Thread Torque Values

Size	Max. Torque Values
1/8", 1/4" (3.8mm)	13.3 in - lbs. (1.5 Nm)
3/8", 1/2" (10, 15mm)	26.6 in - lbs. (3.0 Nm)

## Approvals



**FDA:** Watts AquaLock™ Mini fittings are produced from FDA approved materials.



**NSF/ANSI 61-G:** Watts AquaLock™ Mini fitting products are tested, certified, and approved for contact with drinking water.

Lead free product is certified to NSF/ANSI 372 and conforms with the lead content requirements for lead free plumbing as defined by California, Vermont, Maryland, and Louisiana state laws and the U.S. Safe Drinking Water Act.

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

**Watts AquaLock™ Mini fittings** are designed and manufactured to be trouble free for many years of service life. Mini fitting products are designed and manufactured in polypropylene, a rugged thermoplastic polymer. All Mini fitting products are approved and certified to NSF-61-G. Mini fitting products are available in standard imperial inch sizes. The Watts AquaLock™ design allows for quick and easy connections without installation tools. Simply cut the plastic or copper piping and snap a Watts AquaLock™ fitting in place for a zero leak connection.

Watts AquaLock™ Mini fittings are designed for low pressure fluids. For other applications please refer to our Technical Service Department. Tubing should be supported at minimum of 36" to prevent excessive load to the connectors. Do not install tubing supports closer than 3 inches from the connector ends. We strongly recommend that new installations be thoroughly tested prior to use. Do not use with explosive gases, petroleum products, or other fuels.

## ⚠ CAUTION

The polypropylene material used in the AquaLock™ fittings can be compromised by exposure to volatile organic compounds (VOC's) and caustic chemicals. Therefore, **DO NOT** expose this product to any such chemical or foreign substance, which would include exposure to the following products: **Pipe Dopes (thread sealants)**, bug sprays, lubricants, cleaners, paints, bleaches, acids, solder fluxes, plastic piping primers and cements, oxidizing agents, alkaline solutions, thinners, fuels, oil based caulks, hydrocarbons, spray foam or foaming agents (insulation).


Watts recommends that all fittings and parts be stored in their original packaging until installation to protect the fitting internals from dirt and debris that may cause damage to the o-ring and the o-ring guide.

It is also recommended that all threaded connections be made with Teflon® tape only.

Failure to follow these instructions will void the warranty and possibly result in leaks and water damage.



# Technical Information

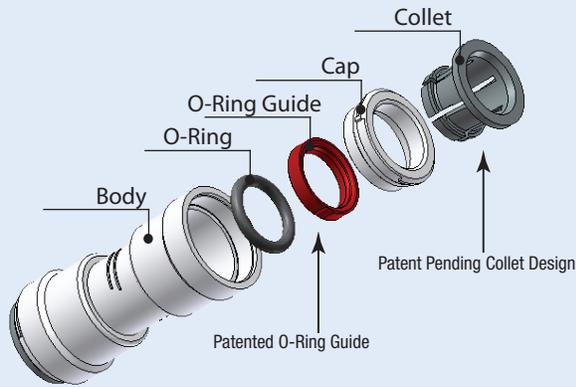

## O-RING GUIDE IS THE KEY!

All AquaLock connectors incorporate an exclusive O-Ring Guide for improved reliability. This unique feature insures zero-leak connections by:

- Protecting the O-Ring from damage during connection
- Increasing the connector's side load capacity
- Correctly aligning the tubing with the O-Ring every time
- Prevents the O-Ring from becoming dislodged



## IAPMO Certified Fittings


The AquaLock Plastic and Brass Series fittings are manufactured in compliance with IAPMO ASSE 1061-2006. With the IAPMO certification, these fittings are approved for domestic and commercial applications for both potable water distribution systems and hydronic heating systems. These fittings can also be utilized in underground applications and as manufactured joints without access panels. To be installed in accordance with the manufacturer's instructions and the latest edition of the Uniform Plumbing Code.

\* If PEX tubing is used, then a tube support liner must be used also



## Rotates under pressure!

After a joint is made, the tubing can still swivel while connected – even under maximum pressure. The ability to rotate under pressure makes these connectors ideal for vibrating and dynamic applications.

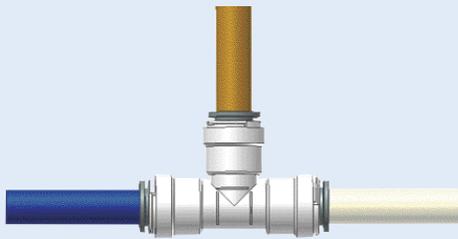

## Connect to Multiple Materials!

The AquaLock fittings incorporate Stainless Steel Gripping Teeth in the Collets. These corrosion resistant teeth allow AquaLock connectors to interconnect with multiple materials without the need for special tools or tube inserts.

- Copper
- CPVC
- PEX, LDPE, MDPE, & HDPE Tubings
- Polybutylene



## Create mini-manifolds!

With AquaLock fittings, small lengths of tubing can be eliminated by using our stackable connector configurations. Simply snap together Tees and/or Elbows to create a mini-manifold of fittings. Because AquaLock connectors rotate, the direction of the tubing can be oriented by a simple twist, reducing the amount of tubing required to plumb a water system.



## Highest Flow!

AquaLock connectors join the tubing on the outside. Because there is no barb fitting on the inside of the tubing the flow capacity is increased by more than 30%. Only AquaLock connectors offer complete flow, allowing for a more efficient system.

## Size and Abbreviation

### Cross Reference

3/8" CTS	1/2" OD
1/2" CTS	5/8" OD
3/4" CTS	7/8" OD
1" CTS	9/8" OD
NPT	National Pipe Thread Tapered
BSP	British Straight Pipe Thread
FGHT	Female Garden Hose Thread
MGHT	Male Garden Hose Thread
NPS	National Pipe Thread Straight
Closet	Toilet Connection
CTS	Copper Tube Size



# Tubing for Plastic Series Fittings

## PEX Tubing

### LEAD FREE\*

AquaLock tubing is produced from a high performance, cross-linked Polyethylene material. AquaLock tubing is formulated and manufactured in 3/8" CTS (1/2" O.D.), 1/2" CTS (5/8" O.D.), 3/4" CTS (7/8" O.D.), and 1" CTS (9/8" O.D.) sizes. AquaLock tubing is NSF listed, FDA recognized and available in multiple colors for ease of water line identification.

#### Tubing Performance Rating:

Operating Pressure: Vacuum to 160psi  
 Max Temperature: 180°F @ 100psi  
 72°F @ 160psi



3/8" and 1/2" CTS 50' coils are packaged in a dispensing box.

#### CUTTER

PART NO. 1158-1522



#### REPLACEMENT BLADE

PART NO. 1161-1522



## IAPMO Certified Fittings

To be compliant with IAPMO ASSE 1061-2006, when using PEX tubing, a tube support liner must be used also.



Model	Description
	<b>*Imperial PEX</b>
WPTC06-100B	PEX Tubing 3/8"CTS Blue 100' Coil
WPTC06-100R	PEX Tubing 3/8"CTS Red 100' Coil
WPF08-50B	PEX Tubing 1/2"CTS Blue 10' Straight Length, 50 Sticks (500' Bundle)
WPTS08-50B	PEX Tubing 1/2"CTS Blue 20' Straight Length, 50 Sticks (1000' Bundle)
WPTC08-100B	PEX Tubing 1/2"CTS Blue 100' Coil
WPTC08-250B	PEX Tubing 1/2"CTS Blue 250' Coil
WPF08-50R	PEX Tubing 1/2"CTS Red 10' Straight Length, 50 Sticks (500' Bundle)
WPTS08-50R	PEX Tubing 1/2"CTS Red 20' Straight Length, 50 Sticks (1000' Bundle)
WPTC08-100R	PEX Tubing 1/2"CTS Red 100' Coil
WPTC08-250R	PEX Tubing 1/2"CTS Red 250' Coil
WPF08-50W	PEX Tubing 1/2"CTS White 10' Straight Length, 50 Sticks (500' Bundle)
WPTS08-50W	PEX Tubing 1/2"CTS White 20' Straight Length, 50 Sticks (1000' Bundle)
WPTC08-100W	PEX Tubing 1/2"CTS White 100' Coil
WPTC08-250W	PEX Tubing 1/2"CTS White 250' Coil
WPF12-25B	PEX Tubing 3/4"CTS Blue 10' Straight Length, 25 Sticks (250' Bundle)
WPTS12-25B	PEX Tubing 3/4"CTS Blue 20' Straight Length, 25 Sticks (500' Bundle)
WPTC12-100B	PEX Tubing 3/4"CTS Blue 100' Coil
WPF12-25R	PEX Tubing 3/4"CTS Red 10' Straight Length, 25 Sticks (250' Bundle)
WPTS12-25R	PEX Tubing 3/4"CTS Red 20' Straight Length, 25 Sticks (500' Bundle)
WPTC12-100R	PEX Tubing 3/4"CTS Red 100' Coil
WPF12-25W	PEX Tubing 3/4"CTS White 10' Straight Length, 25 Sticks (250' Bundle)
WPTS12-25W	PEX Tubing 3/4"CTS White 20' Straight Length, 25 Sticks (500' Bundle)
WPTC12-100W	PEX Tubing 3/4"CTS White 100' Coil
WPTC12-250W	PEX Tubing 3/4"CTS White 250' Coil
WPTC16-100W	PEX Tubing 1"CTS White 100' Coil
WPTS16-5W	PEX Tubing 1"CTS White 20' Straight Length, 5 Sticks (100' Bundle)

\*Metric PEX is on page 16.

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Mini Series

## INTRODUCTION

AquaLock is proud to introduce the new Mini Series polypropylene fittings for POU installations and drinking water systems, beverage service, and water filtration applications.

## Technical Information

Temperature and Pressure:

Max. Pres. 150psi @ 70°F (10.3 bar @ 20°C)

Max. Temp. 60psi @ 140°F (4.1 bar @ 60°C)

Min. Temp. 33°F (0.5°C)

ANSI/NSF-61 approved

Mini Series fittings are made from FDA approved materials



For use with PEX, Polyethylene, Nylon, Polypropylene, Polyurethane, Copper, Brass, and mild steel tubing.

## UNION TEES

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1023-04	81900072 / 840213094560	1/4" OD
1023-06	81900077 / 840213094287	3/8" OD
1023-08	81900089 / 840213094294	1/2" OD

## REDUCING TEES

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1024R-060604	81900107 / 840213094300	3/8" OD x 3/8" OD x 1/4" OD
1024R-080806	81900108 / 840213094317	1/2" OD x 1/2" OD x 3/8" OD

## UNION ELBOWS

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1017-04	81900073 / 840213094324	1/4" OD
1017-06	81900076 / 840213094331	3/8" OD
1017-08	81900123 / 840213094348	1/2" OD

## REDUCING UNION ELBOW

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1017R-0604	81900128 / 840213094539	3/8" OD x 1/4" OD

## STACKABLE ELBOWS

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1018-04	81900124 / 840213094492	1/4" OD
1018-06	81900125 / 840213094508	3/8" OD
1018-08	81900126 / 840213094515	1/2" OD

## MALE ELBOWS

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1019-0402	81900099 / 840213094638	1/4" OD x 1/8" NPTF
1019-0404	81900096 / 840213094621	1/4" OD x 1/4" NPTF
1019-0406	81900109 / 840213094645	1/4" OD x 3/8" NPTF
1019-0604	81900097 / 840213094454	3/8" OD x 1/4" NPTF
1019-0606	81900098 / 840213094461	3/8" OD x 3/8" NPTF
1019-0806	81900091 / 840213094478	1/2" OD x 3/8" NPTF
1019-0808	81900092 / 840213094485	1/2" OD x 1/2" NPTF

## UNION CONNECTORS

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1015-04	81900075 / 840213094577	1/4" OD
1015-06	81900074 / 840213094249	3/8" OD
1015-08	81900090 / 840213094256	1/2" OD

## REDUCING UNION CONNECTORS

**LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1015R-0604	81900095 / 840213094263	3/8" OD x 1/4" OD
1015R-0806	81900122 / 840213094270	1/2" OD x 3/8" OD

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

**FEMALE CONNECTORS** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1010-0401	81900105 / 840213094355	1/4" OD x 7/16" UNS
1010-0601	81900106 / 840213094362	3/8" OD x 7/16" UNS
1010-0404	81900103 / 840213094379	1/4" OD x 1/4" NPTF
1010-0604	81900104 / 840213094386	3/8" OD x 1/4" NPTF

**MALE CONNECTORS** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1001-0402	81900083 / 840213094591	1/4" OD x 1/8" NPTF
1001-0404	81900082 / 840213094584	1/4" OD x 1/4" NPTF
1001-0406	81900084 / 840213094607	1/4" OD x 3/8" NPTF
1001-0408	81900085 / 840213094614	1/4" OD x 1/2" NPTF
1001-0602	81900100 / 840213094393	3/8" OD x 1/8" NPTF
1001-0604	81900087 / 840213094409	3/8" OD x 1/4" NPTF
1001-0606	81900086 / 840213094416	3/8" OD x 3/8" NPTF
1001-0608	81900088 / 840213094423	3/8" OD x 1/2" NPTF
1001-0806	81900093 / 840213094430	1/2" OD x 3/8" NPTF
1001-0808	81900094 / 840213094447	1/2" OD x 1/2" NPTF

**REDUCING STEM** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1014R-0604	81900127 / 840213094522	3/8" OD x 1/4" OD

**MALE STEMS** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1027-0402	81906431 / 840213094188	1/4" OD x 1/8" NPTF
1027-0404	81906432 / 840213094195	1/4" OD x 1/4" NPTF
1027-0604	81906433 / 840213094201	3/8" OD x 1/4" NPTF
1027-0606	81900119 / 840213094218	3/8" OD x 3/8" NPTF
1027-0806	81900120 / 840213094225	1/2" OD x 3/8" NPTF

**END STOPS** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1045-04	81900121 / 840213094232	1/4" OD

**STOP VALVES** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1039-04	81900079 / 840213094164	1/4" OD
1039-06	81900078 / 840213094171	3/8" OD

**MALE STOP VALVES** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1062-04	81900081 / 840213094140	1/4" OD x 1/4" NPTF
1062-06	81900080 / 840213094157	3/8" OD x 3/8" NPTF

**FEMALE STOP VALVES** **LEAD FREE\***



MODEL	EDP/UPC CODE	SIZE & CONNECTION
1053-0404	81900101 / 840213094546	1/4" OD x 1/4" NPTF
1053-0604	81900102 / 840213094553	3/8" OD x 1/4" NPTF

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Plastic Series

Sizes 3/8" - 1/2" - 3/4" - 1" CTS

**AquaLock Plastic Series** is designed and manufactured in Polysulfone—a high-performance thermal plastic material—for many years of trouble-free service life. The majority of Plastic Series products are approved and certified to NSF-61, NSF-14, CSA B137.5, ASTM F877, and IAPMO ASSE 1061-2006 and to the Uniform Plumbing Code (U.P. Code). Plastic Series products are available in standard imperial inch. AquaLock's push-to-connect design allows for quick and easy connections without installation tools; simply cut the plastic, copper, or CPVC piping and snap the AquaLock fitting in place for a zero-leak connection.

\*For item specific listings and approvals, please reference our engineering sheets on [Watts.com](http://Watts.com)

**FITTINGS PERFORMANCE RATING:**  
 Max. Pres. 250psi @ 75°F (17.25 bar @ 24°C)  
 Max. Temp. 100psi @ 180°F (6.8 bar @ 82°C)  
 Min. Temp. 33°F (0.5°C)

AquaLock connectors utilize a swivel nut with NPS straight threads and a cone seal. This allows the installer to thread onto NPT, NPS, BSP, and most other threads without tools or thread sealant. Simply thread on, hand tight, for a zero-leak seal.



**TUBING** **LEAD FREE\***



For tubing turn to page 3

**POLY TUBING** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
PE1004N-100	1/4" O.D.	100' COIL

**UNION TEE** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3523-08CP	3/8" CTS	CONTRACTOR PACK
3523-08	3/8" CTS	SINGLE
3523-10CP	1/2" CTS	CONTRACTOR PACK
3523-10	1/2" CTS	SINGLE
3523-14CP	3/4" CTS	CONTRACTOR PACK
3523-14	3/4" CTS	SINGLE
3523-18CP	1" CTS	CONTRACTOR PACK

**STACKABLE TEE** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3533-08CP	3/8" CTS	CONTRACTOR PACK
3533-08	3/8" CTS	SINGLE
3533-10CP	1/2" CTS	CONTRACTOR PACK
3533-10	1/2" CTS	SINGLE
3533-14CP	3/4" CTS	CONTRACTOR PACK
3533-14	3/4" CTS	SINGLE
3533-18CP	1" CTS	CONTRACTOR PACK

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Sizes 3/8" - 1/2" - 3/4" - 1" CTS

# Plastic Series

## STACKABLE BRANCH TEE **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3534-10CP	1/2" CTS	CONTRACTOR PACK
3534-10	1/2" CTS	SINGLE

## REDUCING BRANCH STACKABLE TEE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3533R-1004CP	1/2" CTS	1/4" O.D.	CONTRACTOR PACK
3533-1004	1/2" CTS	1/4" O.D.	SINGLE
3533R-1410CP	3/4" CTS	1/2" CTS	CONTRACTOR PACK
3533-1410	3/4" CTS	1/2" CTS	SINGLE

## MALE THREAD TEE **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3530-1008CP	1/2" CTS	1/2" NPT	CONTRACTOR PACK
3530-1008	1/2" CTS	1/2" NPT	SINGLE

## REDUCING BRANCH TEE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3524R-101004CP	1/2" CTS	1/4" O.D.	CONTRACTOR PACK
3524R-101004	1/2" CTS	1/4" O.D.	SINGLE
3524R-141410CP	3/4" CTS	1/2" CTS	CONTRACTOR PACK
3524R-141410	3/4" CTS	1/2" CTS	SINGLE
3524R-181814CP	1" CTS	3/4" CTS	CONTRACTOR PACK
3524R-181814	1" CTS	3/4" CTS	SINGLE

## REDUCING RUN TEE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3526R-141410CP	3/4" CTS	1/2" CTS	CONTRACTOR PACK
3526R-141410	3/4" CTS	1/2" CTS	SINGLE

## STACKABLE ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3518-08CP	3/8" CTS	CONTRACTOR PACK
3518-08	3/8" CTS	SINGLE
3518-10CP	1/2" CTS	CONTRACTOR PACK
3518-10	1/2" CTS	SINGLE
3518-14CP	3/4" CTS	CONTRACTOR PACK
3518-14	3/4" CTS	SINGLE
3518-18CP	1" CTS	CONTRACTOR PACK

## UNION ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3517-08CP	3/8" CTS	CONTRACTOR PACK
3517-08	3/8" CTS	SINGLE
3517-10CP	1/2" CTS	CONTRACTOR PACK
3517-10	1/2" CTS	SINGLE
3517-14CP	3/4" CTS	CONTRACTOR PACK
3517-14	3/4" CTS	SINGLE
3517-18CP	1" CTS	CONTRACTOR PACK
3517-18	1" CTS	SINGLE

## UNION CONNECTOR **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3515-08CP	3/8" CTS	CONTRACTOR PACK
3515-08	3/8" CTS	SINGLE
3515-10CP	1/2" CTS	CONTRACTOR PACK
3515-10	1/2" CTS	SINGLE
3515-14CP	3/4" CTS	CONTRACTOR PACK
3515-14	3/4" CTS	SINGLE
3515-18CP	1" CTS	CONTRACTOR PACK
3515-18	1" CTS	SINGLE

## REDUCING UNION ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3517-1410	3/4" CTS	1/2" CTS	SINGLE

## DROP EAR ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3521-1008CP	1/2" CTS	1/2" NPT	CONTRACTOR PACK
3521-1008	1/2" CTS	1/2" NPT	SINGLE

## FLANGE MOUNT ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3568-0810CP	1/2" CTS	1/2" NPS	CONTRACTOR PACK
3568-0810	1/2" CTS	1/2" NPS	SINGLE

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Plastic Series

Sizes 3/8" - 1/2" - 3/4" - 1" CTS

## REDUCING UNION **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3515R-1004CP	1/2" CTS	1/4" O.D.	CONTRACTOR PACK
3516R-1004	1/2" CTS	1/4" O.D.	SINGLE
3515R-1008CP	1/2" CTS	3/8" CTS	CONTRACTOR PACK
3516R-1008	1/2" CTS	3/8" CTS	SINGLE
3515R-1410CP	3/4" CTS	1/2" CTS	CONTRACTOR PACK
3516R-1410	3/4" CTS	1/2" CTS	SINGLE
3515-1814CP	1" CTS	3/4" CTS	CONTRACTOR PACK
3515R-1814CP	1" CTS	3/4" CTS	SINGLE

## END STOP **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3545-08CP	3/8" CTS	CONTRACTOR PACK
3545-08	3/8" CTS	SINGLE
3545-10CP	1/2" CTS	CONTRACTOR PACK
3545-10	1/2" CTS	SINGLE
3545-14CP	3/4" CTS	CONTRACTOR PACK
3545-14	3/4" CTS	SINGLE
3545-18CP	1" CTS	CONTRACTOR PACK
3545-18	1" CTS	SINGLE

## FEMALE CONNECTOR **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3510-0808CP	3/8" CTS	1/2" NPS	CONTRACTOR PACK
3510-0808	3/8" CTS	1/2" NPS	SINGLE
3510-0814CP	3/8" CTS	3/4" FGHT	CONTRACTOR PACK
3510-0814	3/8" CTS	3/4" FGHT	SINGLE
3510-1008CP	1/2" CTS	1/2" NPS	CONTRACTOR PACK
3510-1008	1/2" CTS	1/2" NPS	SINGLE
3510-1012CP	1/2" CTS	3/4" NPS	CONTRACTOR PACK
3510-1012	1/2" CTS	3/4" NPS	SINGLE
3510-1013CP	1/2" CTS	3/4" CLOSET	CONTRACTOR PACK
3510-1013	1/2" CTS	3/4" CLOSET	SINGLE
3510-1014CP	1/2" CTS	3/4" FGHT	CONTRACTOR PACK
3510-1014	1/2" CTS	3/4" FGHT	SINGLE
3510-1412CP	3/4" CTS	3/4" NPS	CONTRACTOR PACK
3510-1412	3/4" CTS	3/4" NPS	SINGLE
3510-1816CP	1" CTS	1" NPS	CONTRACTOR PACK
3510-1816	1" CTS	1" NPS	SINGLE

## FEMALE SWIVEL ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3520-0808CP	3/8" CTS	1/2" NPS	CONTRACTOR PACK
3520-0808	3/8" CTS	1/2" NPS	SINGLE
3520-1008CP	1/2" CTS	1/2" NPS	CONTRACTOR PACK
3520-1008	1/2" CTS	1/2" NPS	SINGLE
3520-1012CP	1/2" CTS	3/4" NPS	CONTRACTOR PACK
3520-1012	1/2" CTS	3/4" NPS	SINGLE
3520-1013	1/2" CTS	3/4" CLOSET	SINGLE
3520-1014CP	1/2" CTS	3/4" FGHT	CONTRACTOR PACK
3520-1014	1/2" CTS	3/4" FGHT	SINGLE

## REDUCING STEM **LEAD FREE\***



MODEL	STEM SIZE	TUBE SIZE	PACKAGE
3514-1008CP	1/2" CTS	3/8" CTS	CONTRACTOR PACK
3514-1008	1/2" CTS	3/8" CTS	SINGLE
3514-1410CP	3/4" CTS	1/2" CTS	CONTRACTOR PACK
3514-1410	3/4" CTS	1/2" CTS	SINGLE
3514-1810CP	1" CTS	1/2" CTS	CONTRACTOR PACK
3514-1814	1" CTS	3/4" CTS	SINGLE
3514-1814CP	1" CTS	3/4" CTS	CONTRACTOR PACK
3514-1814	1" CTS	3/4" CTS	SINGLE

## MALE CONNECTOR **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3501-0806CP	3/8" CTS	3/8" NPT	CONTRACTOR PACK
3501-0806	3/8" CTS	3/8" NPT	SINGLE
3501-0808CP	3/8" CTS	1/2" NPT	CONTRACTOR PACK
3501-0808	3/8" CTS	1/2" NPT	SINGLE
3501-1006CP	1/2" CTS	3/8" NPT	CONTRACTOR PACK
3501-1006	1/2" CTS	3/8" NPT	SINGLE
3501-1008CP	1/2" CTS	1/2" NPT	CONTRACTOR PACK
3501-1008	1/2" CTS	1/2" NPT	SINGLE
3501-1012CP	1/2" CTS	3/4" NPT	CONTRACTOR PACK
3501-1012	1/2" CTS	3/4" NPT	SINGLE
3501-1014CP	1/2" CTS	3/4" MGHT	CONTRACTOR PACK
3501-1014	1/2" CTS	3/4" MGHT	SINGLE
3501-1412CP	3/4" CTS	3/4" NPT	CONTRACTOR PACK
3501-1412	3/4" CTS	3/4" NPT	SINGLE
3501-1816CP	1" CTS	1" NPT	CONTRACTOR PACK

## MALE ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3519-1006CP	1/2" CTS	3/8" NPT	CONTRACTOR PACK
3519-1006	1/2" CTS	3/8" NPT	SINGLE
3519-1008CP	1/2" CTS	1/2" NPT	CONTRACTOR PACK
3519-1008	1/2" CTS	1/2" NPT	SINGLE
3519-1412	3/4" CTS	3/4" NPT	SINGLE
3519-1816	1" CTS	1" NPT	SINGLE
3519-1816CP	1" CTS	1" NPT	CONTRACTOR PACK
3519-1816	1" CTS	1" NPT	SINGLE

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Sizes 3/8" - 1/2" - 3/4" - 1" CTS

# Plastic Series

## UNION PUMP FITTING **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3575-10CP	1/2" CTS	CONTRACTOR PACK

## ELBOW PUMP FITTING **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3576-10CP	1/2" CTS	CONTRACTOR PACK
3576-10	1/2" CTS	SINGLE

## STACKABLE HOSE BARB UNION **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3511-1008CP	1/2" CTS	1/2" H.B.	CONTRACTOR PACK
3511-1008	1/2" CTS	1/2" H.B.	SINGLE

## STACKABLE HOSE BARB ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3512-1008CP	1/2" CTS	1/2" H.B.	CONTRACTOR PACK
3512-1008	1/2" CTS	1/2" H.B.	SINGLE

## HOSE BARB FITTING **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3513-1008CP	1/2" CTS	1/2" H.B.	CONTRACTOR PACK
3513-1008	1/2" CTS	1/2" H.B.	SINGLE
3513-1412CP	3/4" CTS	3/4" H.B.	CONTRACTOR PACK
3513-1412	3/4" CTS	3/4" H.B.	SINGLE
3513-1816	1" CTS	1" H.B.	SINGLE

## MALE STEM **LEAD FREE\***



MODEL	STEM SIZE	THREAD SIZE	PACKAGE
3527-1008CP	1/2" CTS	1/2" NPT	CONTRACTOR PACK
3527-1008	1/2" CTS	1/2" NPT	SINGLE
3527-1416CP	3/4" CTS	1" NPT	CONTRACTOR PACK

## FEMALE STEM **LEAD FREE\***



MODEL	STEM SIZE	THREAD SIZE	PACKAGE
3528-1008CP	1/2" CTS	1/2" NPS	CONTRACTOR PACK
3528-1008	1/2" CTS	1/2" NPS	SINGLE

## TYPE 39 IN-LINE VALVE **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3539-08CP	3/8" CTS	CONTRACTOR PACK
3539-08	3/8" CTS	SINGLE
3539-10CP	1/2" CTS	CONTRACTOR PACK
3539-10	1/2" CTS	SINGLE
3539-14CP	3/4" CTS	CONTRACTOR PACK
3539-14	3/4" CTS	SINGLE
3539-18CP	1" CTS	CONTRACTOR PACK
3539-18	1" CTS	SINGLE

## TYPE 39 REDUCING VALVE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3539R-1004CP	1/2" CTS	1/4" O.D.	CONTRACTOR PACK
3539-1004	1/2" CTS	1/4" O.D.	SINGLE

## TYPE 59 PANEL MOUNT VALVE **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3559-08CP	3/8" CTS	CONTRACTOR PACK
3559-08	3/8" CTS	SINGLE
3559-10CP	1/2" CTS	CONTRACTOR PACK
3559-10	1/2" CTS	SINGLE

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Plastic Series

Sizes 3/8" - 1/2" - 3/4" - 1" CTS

## TYPE 55 IN-LINE VALVE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3555-1006	1/2" CTS	1/4" CTS	SINGLE
3555-1008	1/2" CTS	3/8" CTS	SINGLE

## TYPE 56 ANGLE VALVE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
3556-1006	1/2" CTS	1/4" CTS	SINGLE
3556-1008	1/2" CTS	3/8" CTS	SINGLE

## TYPE 43 STACKABLE VALVE **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3543-10CP	1/2" CTS	CONTRACTOR PACK
3543-10	1/2" CTS	SINGLE

## TYPE 43 REDUCING STACKABLE VALVE **LEAD FREE\***



MODEL	STEM SIZE	TUBE SIZE	PACKAGE
3543-1004	1/2" CTS	1/4" O.D.	SINGLE

## TYPE 52 FEMALE IN-LINE VALVE **LEAD FREE\***



MODEL	THREAD SIZE	TUBE SIZE	PACKAGE
3552-0806	1/2" NPS	1/4" CTS	SINGLE
3552-0808	1/2" NPS	3/8" CTS	SINGLE

## TYPE 53 FEMALE ANGLE VALVE **LEAD FREE\***



MODEL	THREAD SIZE	TUBE SIZE	PACKAGE
3553-0608	1/2" NPS	1/4" CTS	SINGLE
3553-0808	1/2" NPS	3/8" CTS	SINGLE

## TYPE 54 FEMALE ANGLE VALVE **LEAD FREE\***



MODEL	THREAD SIZE	THREAD SIZE	PACKAGE
3554-1408	1/2" NPS	3/4" MGHT	SINGLE

## TYPE 57 MALE ANGLE VALVE **LEAD FREE\***



MODEL	THREAD SIZE	THREAD SIZE	PACKAGE
3557-1408	1/2" NPT	3/4" MGHT	SINGLE

## TYPE 58 ANGLE VALVE **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
3558-1014	1/2" CTS	3/4" MGHT	SINGLE

## TYPE 51 TEE VALVE **LEAD FREE\***



MODEL	THREAD SIZE	THREAD SIZE	TUBE SIZE
3551-0808	1/2" NPS	1/2" NPT	3/8" CTS

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

**TYPE 50 TEE VALVE** **LEAD FREE\***



MODEL	RUN SIZE	BRANCH SIZE	PACKAGE
3550-0404CP	1/4" OD	1/4" OD	CONTRACTOR PACK
3550-0404	1/4" OD	1/4" OD	SINGLE
3550-1004CP	1/2" CTS	1/4" OD	CONTRACTOR PACK
3550-1004	1/2" CTS	1/4" OD	SINGLE
3550-1008CP	1/2" CTS	3/8" CTS	CONTRACTOR PACK
3550-1008	1/2" CTS	3/8" CTS	SINGLE
3550-1404CP	3/4" CTS	1/4" OD	CONTRACTOR PACK
3550-1404	3/4" CTS	1/4" OD	SINGLE
3550-1508CP	15MM	3/8" CTS	CONTRACTOR PACK
3550-1508	15MM	3/8" CTS	SINGLE

**TYPE 38 SELECTOR VALVE** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3538-10CP	1/2" CTS	CONTRACTOR PACK
3538-10	1/2" CTS	SINGLE

**TYPE 40 UNION CHECK VALVE** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3540-10CP	1/2" CTS	CONTRACTOR PACK
3540-10	1/2" CTS	SINGLE

**TYPE 41 BY-PASS VALVE** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3541-10CP	1/2" CTS	CONTRACTOR PACK
3541-10	1/2" CTS	SINGLE

**O-RING ASSEMBLY** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
35159-08CP	3/8" CTS	CONTRACTOR PACK
35159-10CP	1/2" CTS	CONTRACTOR PACK
35159-14CP	3/4" CTS	CONTRACTOR PACK
35159-18CP	1" CTS	CONTRACTOR PACK

**TYPE 61 ADAPTER STOP VALVE**



MODEL	TUBE SIZE	THREAD SIZE	THREAD SIZE
3561-0604	1/4" OD	3/8" MALE COMP	3/8" FEMALE COMP
3561-0606	3/8" OD	3/8" MALE COMP	3/8" FEMALE COMP

**COLLET CLIP**



MODEL	TUBE SIZE	PACKAGE
3547-08CP	3/8" CTS	CONTRACTOR PACK
3547-08	3/8" CTS	SINGLE
3547-10CP	1/2" CTS	CONTRACTOR PACK
3547-10	1/2" CTS	SINGLE
3547-14CP	3/4" CTS	CONTRACTOR PACK
3547-14	3/4" CTS	SINGLE
3547-18CP	1" CTS	CONTRACTOR PACK
3547-18	1" CTS	SINGLE

**PIPE CLIP**



MODEL	TUBE SIZE	PACKAGE
2370-1557CP	1/2" CTS	CONTRACTOR PACK
2370-1557	1/2" CTS	SINGLE
2370-2257CP	3/4" CTS	CONTRACTOR PACK
2370-2257	3/4" CTS	SINGLE
2370-2857CP	1" CTS	CONTRACTOR PACK

**CONE SEAL** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
161-08CP	1/2" NPS	CONTRACTOR PACK
161-12CP	3/4" NPS & FGHT	CONTRACTOR PACK

**COLLET COVER**



MODEL	SIZE	COLOR	PACKAGE
3555-08CP	3/8" CTS	WHITE	CONTRACTOR PACK

**TUBE SUPPORT LINER** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3560-08CP	3/8" CTS	CONTRACTOR PACK
3560-10CP	1/2" CTS	CONTRACTOR PACK
3560-14CP	3/4" CTS	CONTRACTOR PACK
3560-18CP	1" CTS	CONTRACTOR PACK

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

AquaLock™ Manifolds operate much like an electrical breaker box. The main water supply lines bring water into the manifold and individual distribution lines move water out to each fixture. All outlets have a built in valve which allows you the ability to stop the water flow to any single fixture without shutting down the entire water system.

The new AquaLock Manifold System utilizes an exclusive modular design. Manifold Sections can be purchased individually and simply snapped together to create the ideal configuration for each application. AquaLock also offers custom configured, pre-assembled manifolds.

## FEATURES

### Performance ratings

100psi @ 180°F    6.8 bar @ 82°C  
 250psi @ 75°F    17.25 bar @ 24°C

Complies with NSF and FDA standards

Available in custom configurations


Includes mounting brackets and labels

All Inlets are 1" CTS (use a Reducing Stem to create other inlet sizes)

**LEAD FREE\***


### Style A

2 AquaLock Inlets

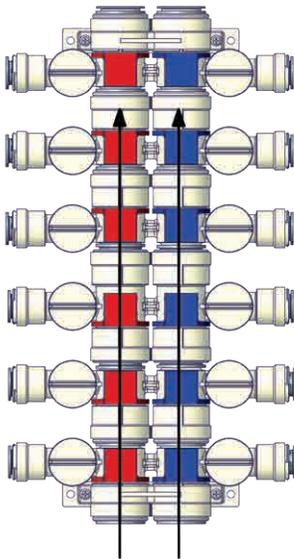


### Style B

1 AquaLock Inlet

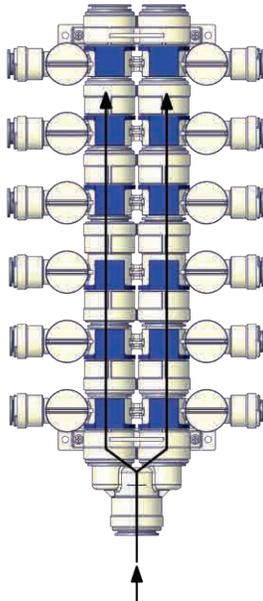


### Style E

2 AquaLock Inlets  
1 AquaLock Outlet

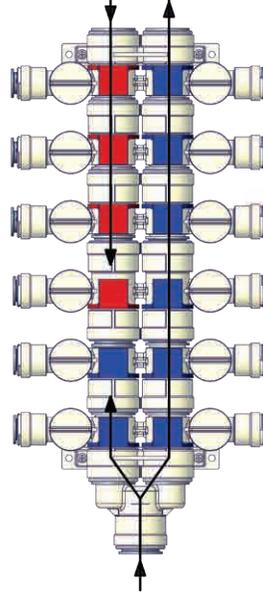


### Style G

2 AquaLock Inlets

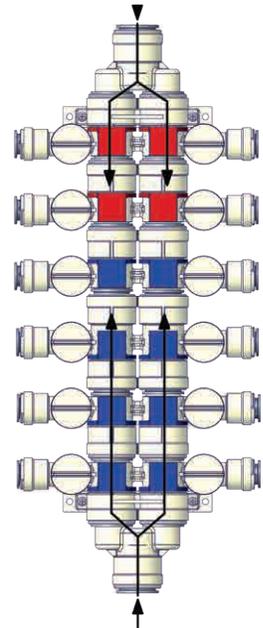


### Style B

1 AquaLock Inlet  
Single Temperature Use (Hot or Cold)

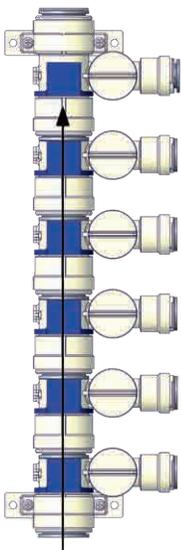


### Style C

2 AquaLock Inlets  
Single Temperature Use (Hot or Cold)

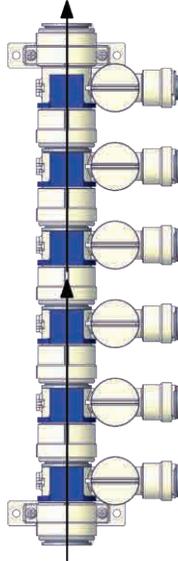

### Style G

2 AquaLock Inlets  
Dual Temperature Use (Hot & Cold)

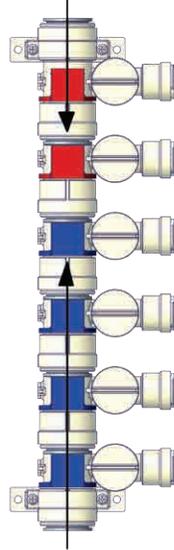

## Ordering Information

D = Dual Side    Inlet Port Style  
 S = Single Side

35 **D** **A**-12 **06**

Total Number of Ports


Total Number of Cold Ports

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.


# Assembly Elements

# Plastic Series Manifold

## DUAL SIDE STYLE

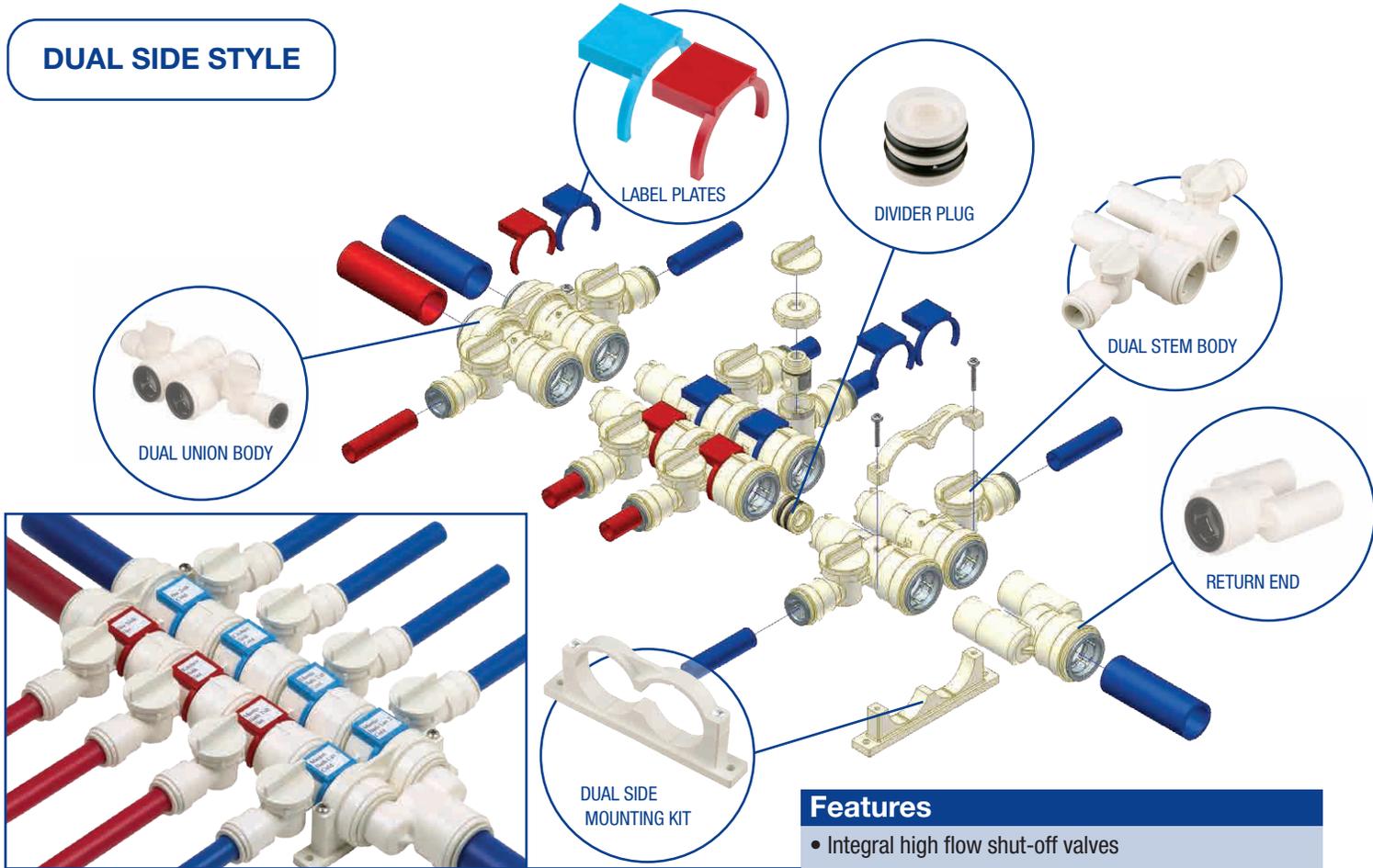

## SINGLE SIDE STYLE

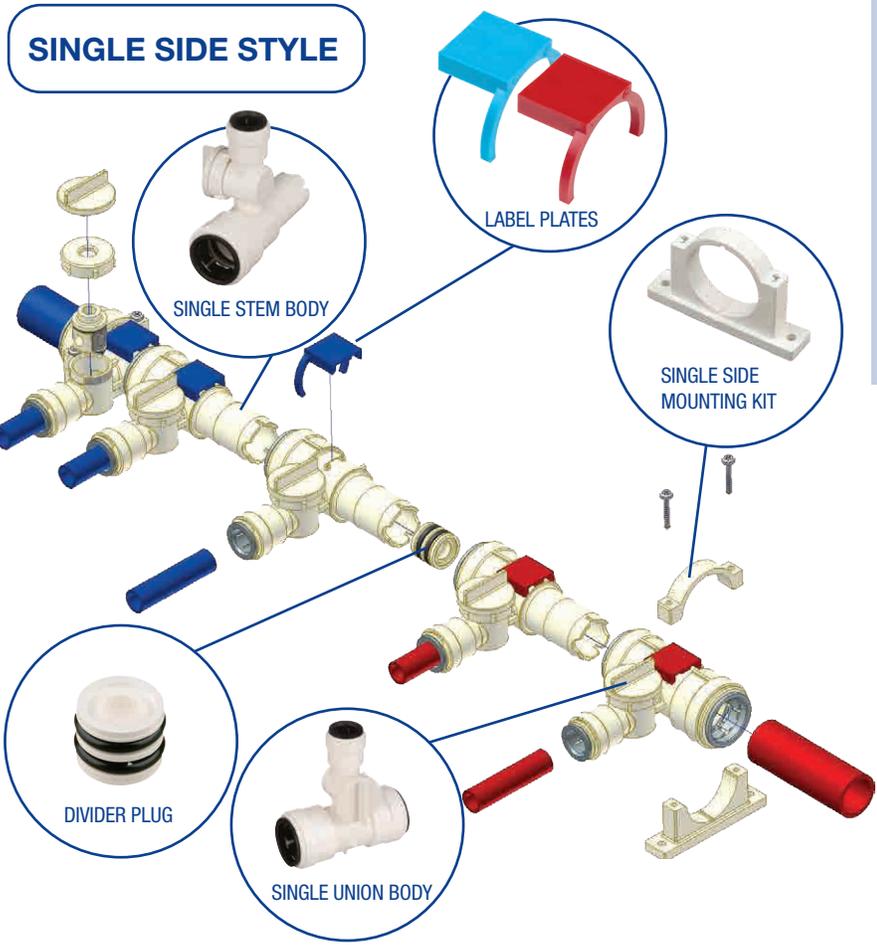

### Features

- Integral high flow shut-off valves
- Serviceable shut-off valves
- Eliminates fittings
- Single and Dual sections can be connected together
- Modular design allows for flexibility
- Field-configurable
- Increase water flow
- Available in single or dual outlet configurations



# Plastic Series Manifold

# Components

## DUAL UNION BODY **LEAD FREE\***



MODEL	BODY SIZE	PORT SIZE	PACKAGE
3583-1810CP	1" CTS	1/2" CTS	CONTRACTOR PACK
3583-1810	1" CTS	1/2" CTS	SINGLE

## DUAL STEM BODY **LEAD FREE\***



MODEL	BODY SIZE	PORT SIZE	PACKAGE
3584-1810CP	1" CTS	1/2" CTS	CONTRACTOR PACK
3584-1810	1" CTS	1/2" CTS	SINGLE

## SINGLE UNION BODY **LEAD FREE\***



MODEL	BODY SIZE	PORT SIZE	PACKAGE
3589-1810CP	1" CTS	1/2" CTS	CONTRACTOR PACK
3589-1810	1" CTS	1/2" CTS	SINGLE

## SINGLE STEM BODY, RIGHT **LEAD FREE\***



MODEL	BODY SIZE	PORT SIZE	PACKAGE
3590-1810	1" CTS	1/2" CTS	CONTRACTOR PACK

## SINGLE STEM BODY, LEFT **LEAD FREE\***



MODEL	BODY SIZE	PORT SIZE	PACKAGE
3591-1810CP	1" CTS	1/2" CTS	CONTRACTOR PACK

## REDUCING STEM **LEAD FREE\***



MODEL	STEM SIZE	TUBE SIZE	PACKAGE
3514-1814CP	1" CTS	3/4" CTS	CONTRACTOR PACK
3514-1810CP	1" CTS	1/2" CTS	CONTRACTOR PACK

## END STOP **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
3545-18CP	1" CTS	CONTRACTOR PACK

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

## END PLUG **LEAD FREE\***



MODEL	STEM SIZE	PACKAGE
3546-18CP	1" CTS	CONTRACTOR PACK
3546-18	1" CTS	SINGLE

## DUAL SIDE MOUNTING KIT



MODEL	PACKAGE
3580-18CP	CONTRACTOR PACK

\*Note: Stainless Bracket Screws Included

## SINGLE SIDE MOUNTING KIT



MODEL	PACKAGE
3581-18CP	CONTRACTOR PACK

\*Note: Stainless Bracket Screws Included

## DIVIDER PLUG **LEAD FREE\***




MODEL	PACKAGE
3582-18CP	CONTRACTOR PACK

## RETURN END **LEAD FREE\***



MODEL	STEM SIZE	PACKAGE
3585-18CP	1" CTS	CONTRACTOR PACK
3585-18	1" CTS	SINGLE

## LABEL PLATE

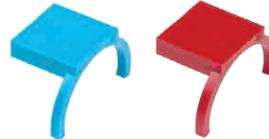

MODEL	COLOR	PACKAGE
3586-18CP	RED	CONTRACTOR PACK
3586-18	RED	SINGLE
3587-18CP	BLUE	CONTRACTOR PACK
3587-18	BLUE	SINGLE

## VALVE REPAIR KIT **LEAD FREE\***




MODEL	SPOOL SIZE	PACKAGE
3588-10CP	1/2"	CONTRACTOR PACK
3588-10	1/2"	SINGLE

## MANIFOLD WRENCH



MODEL	BODY SIZE	PACKAGE
351192-18CP	1" CTS	CONTRACTOR PACK

\*Note: For Ease of Disconnection

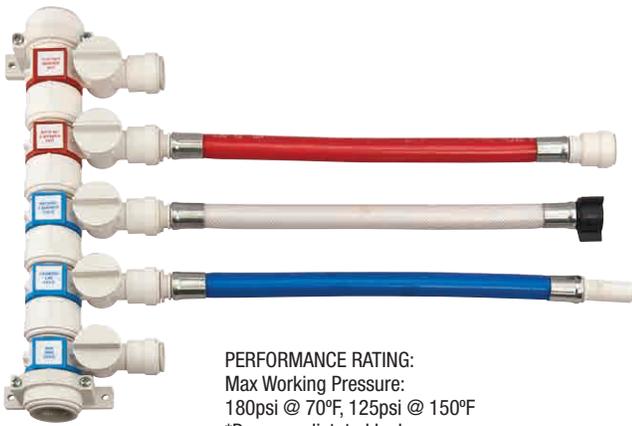

PERFORMANCE RATING:  
 Max Working Pressure:  
 180psi @ 70°F, 125psi @ 150°F  
 \*Pressure dictated by hose

The Uniflex Hose System is designed for use with the AquaLock™ Plastic Series manifolds, fittings, and valves and PEX tubing. All hoses come pre-assembled to meet individual needs and for ease of plumbing installation. Hoses that use the 1/2" CTS stems quick connect directly into a 1/2" push-to-connect fitting, valve, or manifold. Hoses that incorporate a 1/2" female end can be used for a home run from the manifold to a fixture. Hoses that use our 1/2" push-to-connect end can be used with 1/2" PEX or any of our 1/2" stem fittings to create the ideal connection for your particular use.

### U822535-XX

SIZE	COLOR	END	END
1/2"	Blue	1/2" CTS Stem	1/2" Push-to-Connect



### U820125-XX

SIZE	COLOR	END	END
1/2"	Blue	1/2" Female	1/2" CTS Stem



### U832535-XX

SIZE	COLOR	END	END
1/2"	Red	1/2" CTS Stem	1/2" Push-to-Connect



### U830125-XX

SIZE	COLOR	END	END
1/2"	Red	1/2" Female	1/2" CTS Stem



### U842535-XX

SIZE	COLOR	END	END
1/2"	White	1/2" CTS Stem	1/2" Push-to-Connect



### U840125-XX

SIZE	COLOR	END	END
1/2"	White	1/2" Female	1/2" CTS Stem



### U832525-XX

SIZE	COLOR	END	END
1/2"	Red	1/2" CTS Stem	1/2" CTS Stem



### U822525-XX

SIZE	COLOR	END	END
1/2"	Blue	1/2" CTS Stem	1/2" CTS Stem



### U842525-XX

SIZE	COLOR	END	END
1/2"	White	1/2" CTS Stem	1/2" CTS Stem



## Ordering Information

**U820125-12 UF Hose 1/2" Blue, 1/2" Fem x 1/2" Stem, 1' Long**

<b>U</b>	<b>8</b>	<b>2</b>	<b>01</b>	<b>25</b>	—	<b>12</b>
U Uniflex	8 1/2" ID	2 2 = Blue 3 = Red 4 = White	01 1st Hose End Style 01 = 1/2" Female 25 = 1/2" CTS Stem	25 2nd Hose End Style 25 = 1/2" CTS Stem 35 = 1/2" CTS Push-to-Connect		-12 Length of Hose Listed in Inches (Sold in 1FT Increments)

**Note:** All Uniflex hoses are made to order. Call AquaLock Customer Service for lead times.

# Metric Series

# Sizes 15MM and 22MM



AquaLock Metric Series products are available in sizes 15mm and 22mm. AquaLock offers push-to-connect fittings, valves, modular manifolds and tubing in this world class product offering. AquaLock's Metric Series line is manufactured in several high performance materials that are FDA approved and NSF-61 certified for contact with drinking water.

**FITTING PERFORMANCE RATING:**  
 Operating Pressure: Vacuum to 250psi  
 Max Temperature: 140°F @ 100psi / 75°F @ 250psi



AquaLock connectors utilize a swivel nut with NPS straight threads and a cone seal. This allows the installer to thread onto NPT, NPS, BSP and most 1/2" male threads without tools or thread sealant. Simply thread on, hand tight, for a zero-leak seal.

Cone Seal



Reducing Tees can be developed by simply snap fitting a Reducing Stem Connector into a Union Tee.

Model	Description
<b>Metric PEX</b>	
001550B	PEX Tubing 15MM Blue 50' Coil Box
50241	PEX Tubing 15MM Blue 250' Coil
001550R	PEX Tubing 15MM Red 50' Coil Box
50237	PEX Tubing 15MM Red 250' Coil
001550W	PEX Tubing 15MM White 50' Coil Box
CST50241G	PEX Tubing 15MM Green 250' Coil
50251	PEX Tubing 22MM Blue 50' Coil
50247	PEX Tubing 22MM Red 50' Coil
50243	PEX Tubing 22MM White 50' Coil



AquaLock tubing is produced from a high performance, polyethylene material. AquaLock Tubing is formulated and manufactured in 15MM and 22MM sizes. AquaLock Tubing is NSF listed, FDA recognized and available in multiple colors for ease of water line identification.



15MM 50' coils are packaged in a dispensing box.

**TUBING PERFORMANCE RATING:**  
 Operating Pressure: Vacuum to 160psi  
 Max Temperature: 180°F @ 100psi  
 72°F @ 160psi

## POLY TUBING **LEAD FREE\***



MODEL	TUBE SIZE	COIL SIZE
PE1004N-100	1/4" O.D.	100' COIL

## CUTTER



MODEL
1158-1522

## REPLACEMENT BLADE



MODEL
1161-1522

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Sizes 15MM and 22MM

# Metric Series

**UNION TEE** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1123-1515CP	15MM	CONTRACTOR PACK
1123-1515	15MM	SINGLE
1623-2222CP	22MM	CONTRACTOR PACK

**REDUCING TEE** **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
1624-221515CP	22MM	15MM	CONTRACTOR PACK
1624-222215CP	22MM	15MM	CONTRACTOR PACK

**FEMALE SWIVEL TEE** **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1125-0815CP	15MM	1/2" NPS	CONTRACTOR PACK
1125-0815	15MM	1/2" NPS	SINGLE

**STACKABLE TEE** **LEAD FREE\***



PART NO.	TUBE SIZE	PACKAGE
1133-1515CP	15MM	CONTRACTOR PACK
1133-1515	15MM	SINGLE
1133-2222CP	22MM	CONTRACTOR PACK

**UNION ELBOW** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1117-1515CP	15MM	CONTRACTOR PACK
1117-1515	15MM	SINGLE
1617-2222CP	22MM	CONTRACTOR PACK

**FEMALE SWIVEL ELBOW** **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1120-0815CP	15MM	1/2" NPS	CONTRACTOR PACK
1120-0815	15MM	1/2" NPS	SINGLE
1120-1215CP	15MM	3/4" NPS	CONTRACTOR PACK

**STACKABLE ELBOW** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1118-1515CP	15MM	CONTRACTOR PACK
1118-1515	15MM	SINGLE
1618-2222CP	22MM	CONTRACTOR PACK

**DROP EAR ELBOW** **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1121-0815CP	15MM	1/2" NPT	CONTRACTOR PACK

**REDUCING STEM** **LEAD FREE\***



MODEL	TUBE SIZE	STEM SIZE	PACKAGE
1614-1522CP	15MM	22MM	CONTRACTOR PACK
1614-1522	15MM	22MM	SINGLE

**FLANGE MOUNT ELBOW** **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1168-0815CP	15MM	1/2" NPS	CONTRACTOR PACK
1168-0815	15MM	1/2" NPS	SINGLE

**UNION CONNECTOR** **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1115-1515CP	15MM	CONTRACTOR PACK
1115-1515	15MM	SINGLE
1615-2222CP	22MM	CONTRACTOR PACK

**REDUCING UNION** **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
1116-1015CP	1/2" CTS	15MM	CONTRACTOR PACK
1116-1015	1/2" CTS	15MM	SINGLE

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Metric Series

Sizes 15MM and 22MM

## FEMALE SWIVEL **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1110-0815CP	15MM	1/2" NPS	CONTRACTOR PACK
1110-0815	15MM	1/2" NPS	SINGLE
1110-1215CP	15MM	3/4" NPS	CONTRACTOR PACK
2609-1215CP	15MM	3/4" FGHT	CONTRACTOR PACK
1607-1222CP	22MM	3/4" NPS	CONTRACTOR PACK

## MALE ELBOW **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1119-0815CP	15MM	1/2" NPT	CONTRACTOR PACK

## MALE CONNECTOR **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
2402-0815CP	15MM	1/2" NPT	CONTRACTOR PACK
2902-1222CP	22MM	3/4" NPT	CONTRACTOR PACK

## MALE CONNECTOR (BRASS) **LEAD FREE\***



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
1201-0815CP	15MM	1/2" NPT	CONTRACTOR PACK
1701-1222CP	22MM	3/4" NPT	CONTRACTOR PACK

## COMPRESSION CONNECTOR (BRASS) **LEAD FREE\***



MODEL	TUBE SIZE	NUT SIZE	PACKAGE
LF1212-0615	15MM	3/8"	CONTRACTOR PACK
LF1211-0615	15MM	NONE	CONTRACTOR PACK

## HOSE BARB CONNECTOR **LEAD FREE\***



MODEL	TUBE SIZE	BARB SIZE	PACKAGE
1413-0615CP	15MM	3/8" H.B.	CONTRACTOR PACK
2413-0815CP	15MM	1/2" H.B.	CONTRACTOR PACK
2413-0815	15MM	1/2" H.B.	SINGLE
2913-1222CP	22MM	3/4" H.B.	CONTRACTOR PACK

## MALE STEM (BRASS) **LEAD FREE\***



PART NO.	STEM SIZE	THREAD SIZE	PACKAGE
1229-0815CP	15MM	1/2" NPT	CONTRACTOR PACK

## ELBOW PUMP CONNECTOR **LEAD FREE\***



PART NO.	TUBE SIZE	PACKAGE
2476-15CP	15MM	CONTRACTOR PACK

## UNION PUMP CONNECTOR **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
2475-15CP	15MM	CONTRACTOR PACK

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

## END STOP **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1145-15CP	15MM	CONTRACTOR PACK
1145-15	15MM	SINGLE
1645-22CP	22MM	CONTRACTOR PACK

## END PLUG **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1146-15CP	15MM	CONTRACTOR PACK
1646-22CP	22MM	CONTRACTOR PACK

## STOP VALVE **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
2439-1515CP	15MM	CONTRACTOR PACK
2439-1515	15MM	SINGLE
2939-2222CP	22MM	CONTRACTOR PACK

## REDUCING VALVE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
2439-0415CP	15MM	1/4" O.D.	CONTRACTOR PACK
2439-0415CP	15MM	1/4" O.D.	SINGLE

## STACKABLE VALVE **LEAD FREE\***



MODEL	STEM SIZE	TUBE SIZE	PACKAGE
2443-0415CP	15MM	1/4" O.D.	CONTRACTOR PACK
2440-1515CP	15MM	15MM	CONTRACTOR PACK

## TEE VALVE **LEAD FREE\***



MODEL	TUBE SIZE	TUBE SIZE	PACKAGE
2444-0415CP	15MM	1/4" O.D.	CONTRACTOR PACK
2444-0415	15MM	1/4" O.D.	SINGLE
3550-1508CP	15MM	3/8" CTS	CONTRACTOR PACK
3550-1508	15MM	3/8" CTS	SINGLE

## UNION CHECK VALVE **LEAD FREE\***



MODEL	TUBE SIZE	PACKAGE
1140-15CP	15MM	CONTRACTOR PACK

## MALE STEM CHECK VALVE (BRASS) **LEAD FREE\***



MODEL	STEM SIZE	THREAD SIZE	PACKAGE
1235-0815CP	15MM	1/2" NPT	CONTRACTOR PACK

## STEM CHECK VALVE (BRASS)



PART NO.	STEM SIZE	PACKAGE
LF1237-15CP	15MM	CONTRACTOR PACK

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Metric Series

Sizes 15MM and 22MM

## PIPE CLIP



MODEL	TUBE SIZE	PACKAGE
2370-1557CP	15MM	CONTRACTOR PACK
2370-1557	15MM	SINGLE
2370-2257CP	22MM	CONTRACTOR PACK
2370-2257	22MM	SINGLE

## WASHING MACHINE HOSE KIT



MODEL	TUBE SIZE	THREAD SIZE	PACKAGE
UWM-100-48CP	15MM	3/4" FGHT	CONTRACTOR PACK

## COLLET CLIP



MODEL	TUBE SIZE	PACKAGE
1147-15CP	15MM	CONTRACTOR PACK
1147-15	15MM	SINGLE
1147-22CP	22MM	CONTRACTOR PACK

## MINI UNION TEE (for Poly Tubing) **LEAD FREE\***



PART NO.	TUBE SIZE	PACKAGE
1023-04	1/4" O.D.	SINGLE

## ELECTRIC STEM VALVE (BRASS)



MODEL	TUBE SIZE	VOLT	PACKAGE
12104-0415-12CP	15MM	12VDC	CONTRACTOR PACK
12104-0415-24CP	15MM	24VDC	CONTRACTOR PACK

VALVE IS PACKAGED WITH ONE 1/4" QUICK CONNECT FITTING

## COLLET COVER



MODEL	COLOR	TUBE SIZE	PACKAGE
2154-15CP	RED	15MM	CONTRACTOR PACK
2156-15CP	BLUE	15MM	CONTRACTOR PACK
2957-22CP	BLACK	22MM	CONTRACTOR PACK

## DECK SPRAYER & FITTINGS



MODEL	OUTLET STYLE	PACKAGE
41106CP	SPRAY HEAD	CONTRACTOR PACK
41107-0206CP	1/8" BARB ELBOW	CONTRACTOR PACK

(Thru Deck is packaged with one 1/4" Union Elbow as shown)

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

AquaLock Manifolds operate much like an electrical breaker box. The main water supply lines bring water into the manifold and individual distribution lines move water out to each fixture. All outlets have a built in valve which allows you the ability to stop the water flow to any single fixture without shutting down the entire water system.

The new AquaLock Manifold System utilizes an exclusive modular design. Manifold Sections can be purchased individually and simply snapped together to create the ideal configuration for each application. AquaLock also offers custom configured, pre-assembled manifolds.

## FEATURES

Performance ratings

100psi @ 180°F    6.8 bar @ 82°C  
250psi @ 75°F    17.25 bar @ 24°C

Complies with NSF and FDA standards

Available in custom configurations


Includes mounting brackets and labels

All Inlets are 1" CTS (use a Reducing Stem to create other inlet sizes)

**LEAD FREE\***


### Style A

2 AquaLock Inlets

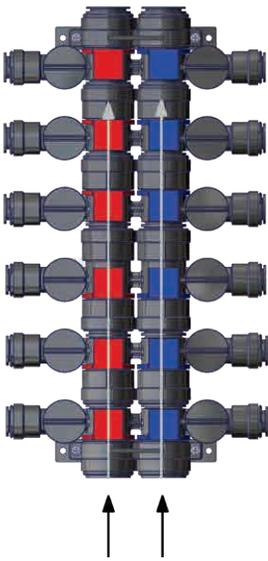


### Style B

1 AquaLock Inlet

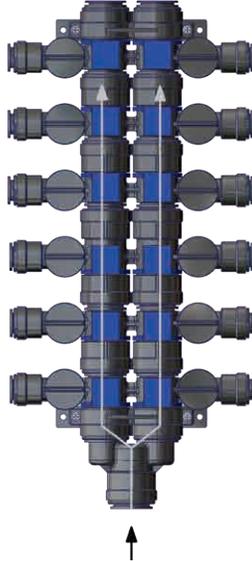


### Style E

2 AquaLock Inlets  
1 AquaLock Outlet

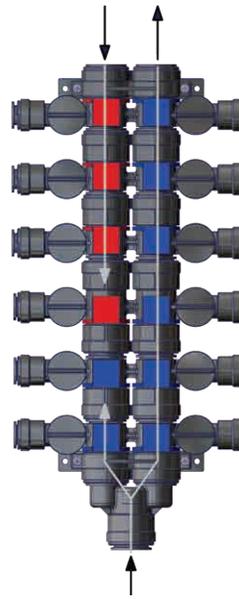


### Style G

2 AquaLock Inlets

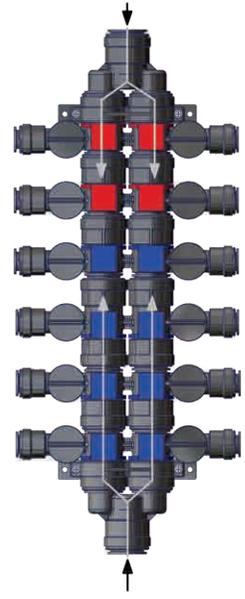


### Style B

1 AquaLock Inlet  
Single Temperature  
Use (Hot or Cold)

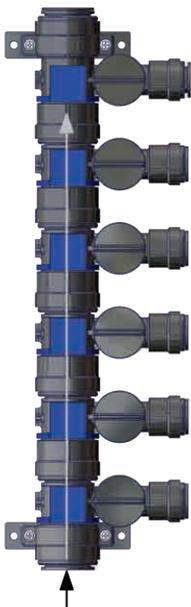


### Style C

2 AquaLock Inlets  
Single Temperature  
Use (Hot or Cold)

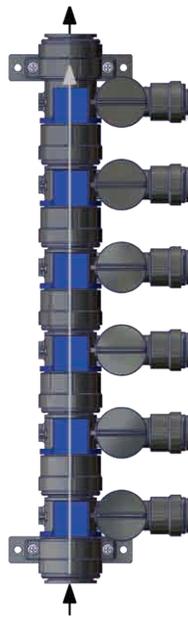

### Style G

2 AquaLock Inlets  
Dual Temperature  
Use (Hot & Cold)

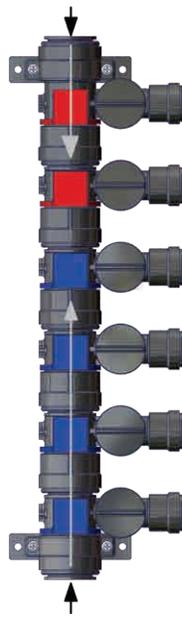

## Ordering Information

D = Dual Side    Inlet Port Style  
S = Single Side

11 DA-12 06

Total Number  
of Ports


Total Number  
of Cold Ports

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.


# Metric Series AquaLock Manifold

## Assembly Elements

### DUAL SIDE STYLE

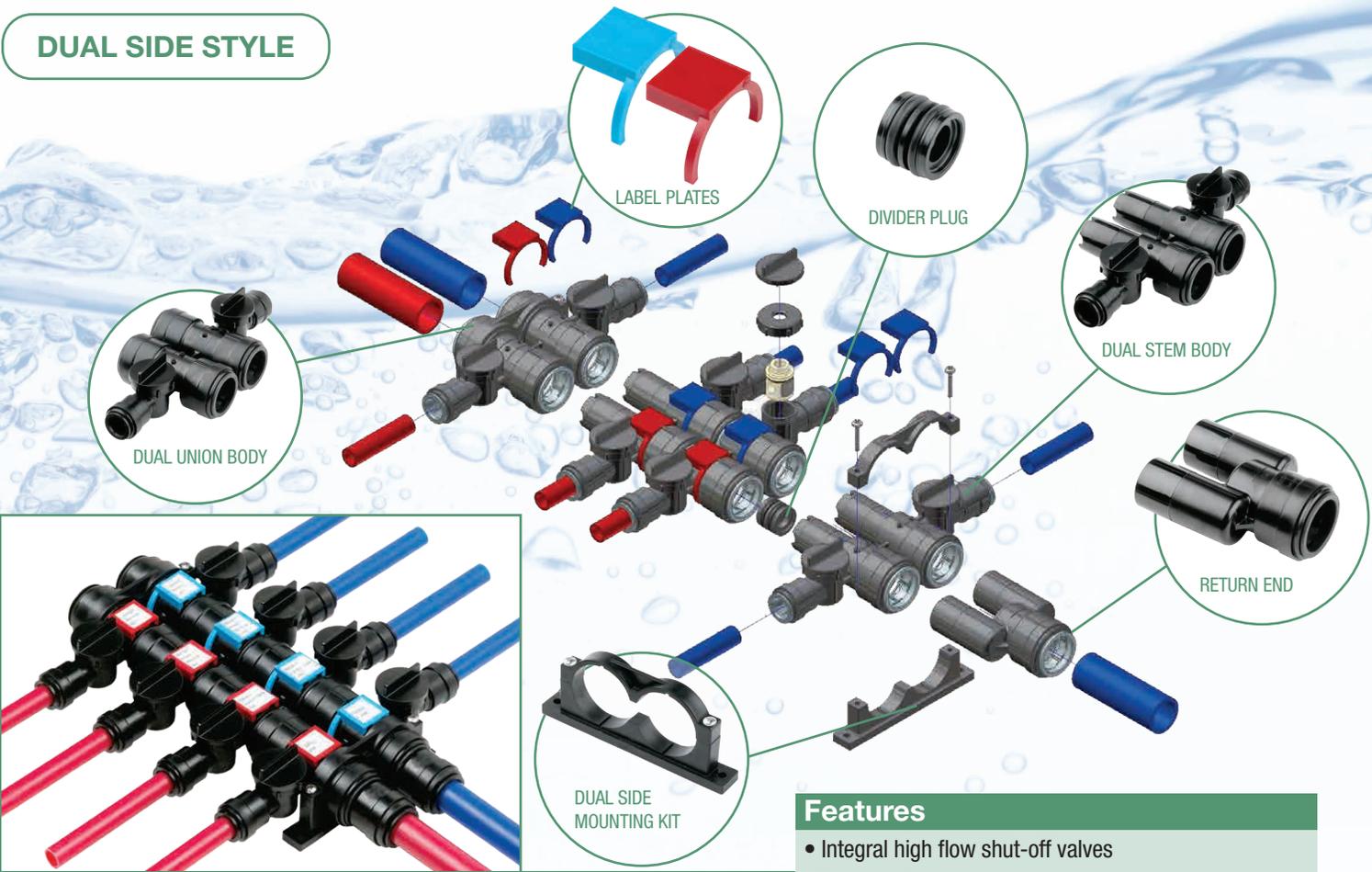

### SINGLE SIDE STYLE

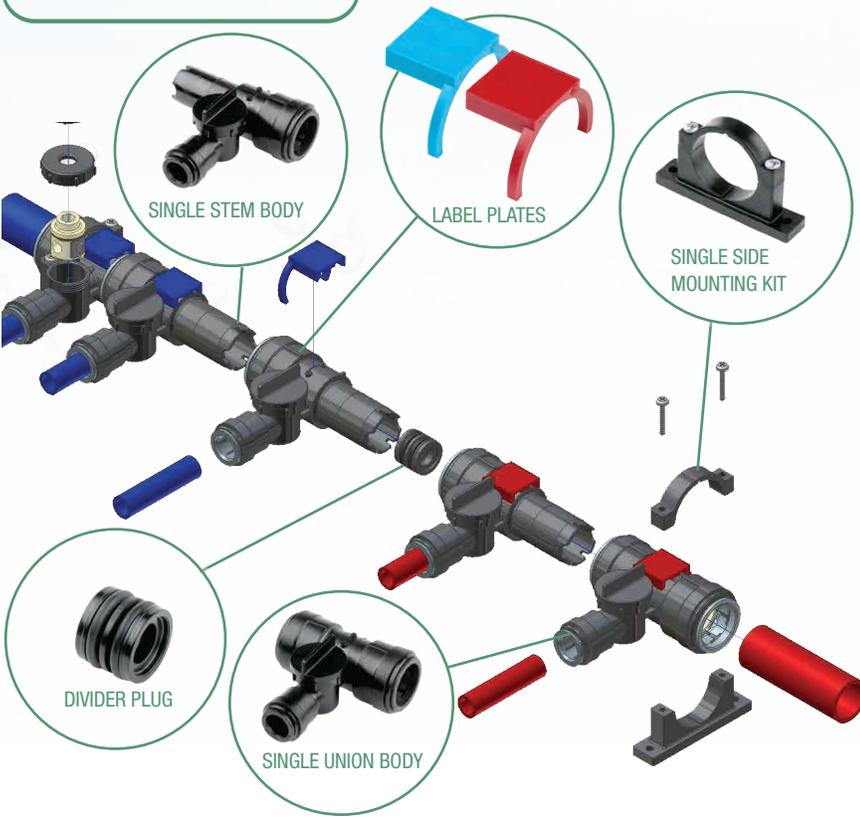

### Features

- Integral high flow shut-off valves
- Serviceable shut-off valves
- Eliminates fittings
- Single and Dual sections can be connected together
- Modular design allows for flexibility
- Field-configurable
- Increase water flow
- Available in single or dual outlet configurations



\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

## DUAL UNION BODY **LEAD FREE\***

MODEL	BODY SIZE	PORT SIZE	PACKAGE
1183-1815	1" CTS	15MM	SINGLE



## DUAL STEM BODY **LEAD FREE\***

MODEL	BODY SIZE	PORT SIZE	PACKAGE
1184-1815	1" CTS	15MM	SINGLE



## SINGLE UNION BODY **LEAD FREE\***

MODEL	BODY SIZE	PORT SIZE	PACKAGE
1189-1815	1" CTS	15MM	SINGLE



## SINGLE STEM BODY, RIGHT **LEAD FREE\***

MODEL	BODY SIZE	PORT SIZE	PACKAGE
1190-1815	1" CTS	15MM	SINGLE



## SINGLE STEM BODY, LEFT **LEAD FREE\***

MODEL	BODY SIZE	PORT SIZE	PACKAGE
1191-1815	1" CTS	15MM	SINGLE



## REDUCING STEM **LEAD FREE\***

MODEL	STEM SIZE	TUBE SIZE	PACKAGE
1114-1822CP	1" CTS	22MM	CONTRACTOR PACK
1114-1815CP	1" CTS	15MM	CONTRACTOR PACK



## END STOP **LEAD FREE\***

MODEL	TUBE SIZE	PACKAGE
1145-18CP	1" CTS	CONTRACTOR PACK



## END PLUG **LEAD FREE\***

MODEL	STEM SIZE	PACKAGE
1146-18	1" CTS	CONTRACTOR PACK



## DUAL SIDE MOUNTING KIT

MODEL	PACKAGE
1180-18CP	CONTRACTOR PACK



\*Note: Stainless Bracket Screws Included

## SINGLE SIDE MOUNTING KIT

MODEL	PACKAGE
1181-18	SINGLE



\*Note: Stainless Bracket Screws Included

## DIVIDER PLUG **LEAD FREE\***

MODEL	PACKAGE
1182-18CP	CONTRACTOR PACK



## RETURN END **LEAD FREE\***

MODEL	STEM SIZE	PACKAGE
1185-18	1" CTS	SINGLE



## LABEL PLATE

MODEL	COLOR	PACKAGE
3586-18CP	RED	CONTRACTOR PACK
3587-18CP	BLUE	CONTRACTOR PACK



## VALVE REPAIR KIT **LEAD FREE\***

MODEL	SPOOL SIZE	PACKAGE
1188-15CP	15MM	CONTRACTOR PACK



## MANIFOLD WRENCH

MODEL	BODY SIZE	PACKAGE
351192-18CP	1" CTS	CONTRACTOR PACK



\*Note: For Ease of Disconnection

\*The wetted surface of this product contacted by consumable water contains less than 0.25% of lead by weight.

# Supercoil System



## SUPERCOIL

High performance U.V. resistant wash-down hose is made from polyurethane tubing, plated brass crimps, and corrosion resistance plastic hose ends. The SuperCoil hose is available in Blue, White, 15ft, 25ft and is guaranteed not to kink or fail.



## SUPERCOIL™

All coils come with U.V. resist plastic garden hose ends.



MODEL	COLOR	LENGTH
EC15201BX	BLUE	15'
EC25201BX	BLUE	25'



MODEL	COLOR	LENGTH
EC15201WX	WHITE	15'
EC25201WX	WHITE	25'



## SPEED-TAP™

Washdown Fitting incorporates an automatic shut-off valve for ease of use and is flush mounted.

MODEL	COLOR
ST301	WHITE HOUSING WITH HOSE ADAPTOR
ST300	WHITE HOUSING WITHOUT HOSE ADAPTOR
ST101	BLACK HOUSING WITH HOSE ADAPTOR
ST100	BLACK HOUSING WITHOUT HOSE ADAPTOR



## SPEED-TAP HOSE ADAPTOR

This unique adaptor threads onto any standard garden hose fitting to interconnect with the Speed-Tap.

MODEL	COLOR
MSP100	WITH AUTO SHUT-OFF
MSP101	NO AUTO SHUT-OFF



## Watts Family of Brands

Watts designs, manufactures, and sells an extensive line of flow control, water safety, water filtration & treatment, drainage, and PEX plumbing products.

The Watts family of companies provides a single source for solutions used to safely convey, conserve, and manage water.

Making Watts your single source for plumbing-related solutions will streamline your operations, save you money, and reduce the variety of repair parts needed for maintenance.

 AERCO®

 AMES  
FIRE & WATERWORKS

 BLÜCHER®

 Dormont®

 FEBCO®

 scientific

 Mueller Steam Specialty™

 ORION®

 POWERS™

 Premier™

 PVi®

 SunTouch®

 tekmar®

 WATTS®

 WATTS®

USA: Tel: (713) 943-0688 • Fax: (713) 944-9445 • Watts.com

Canada: Tel: (905) 332-4090 • Fax: (905) 332-7068 • Watts.ca

Latin America: Tel: (52) 55-4122-0138 • Watts.com