

Engineering Specification

Job Name _____

Contractor Signature _____

Orion Representative _____

Approval Date _____

Quantity Required _____

Contractor's P.O. No. _____

Please email your completed and signed submittal prior to quote or order entry to orientanks@wattswater.com.

T5 Retro-Fit Cylindrical Bolt-On Tank Extension

Specification

Orion T5 Retro-Fit Extension shall be cylindrical, seamless, stress and defect free, rotationally molded construction to uniform wall thickness from virgin PE resins conforming to ASTM D 1248. Extension shall include integral anchor flange for bolting and gasketing to existing tank. **Standard, non-load bearing, domed tank cover shall be bolted and gasketed to tank extension.**

Call customer service if you need assistance with technical details.

Extension Tank Size

SELECTION (CHECK ONE)	BASE TANK CAPACITY (USG)	EXT. HT. (IN)		
		MIN. (A)	MAX. (A)	COVER DIA. (IN.)
	5	4	13	14
	15	4	12.25	20.5
	30	4	25.5	20.5
	55	4	29	26
	100	4	44	27.25
	150	4	44.5	34.5
	180	4	34.5	40
	200	4	45.25	41.25
	275	4	39	44.75
	360	4	39.75	51.75
	500	4	48	57
	600	4	58	53
	1200	4	36	74

COVER OPTIONS	
	Fiberglass Wrap*
	3/4" Plastic Cover
	1/4" Steel x 3/4" Plastic Cover (Not to be used in conjunction w/Access Options)

ACCESS OPTIONS	
	4" Cleanout Access
	6" Cleanout Access
	12" Gamma Top Access
	16" Gamma Top Access
	20" x 3/4" Bolted Access
	24" x 3/4" Bolted Access

⚠ CALIFORNIA PROP 65 WARNING: This product can expose you to chemicals including benzene which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.


Orion Fittings product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Orion Fittings Technical Service. Orion Fittings reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Orion Fittings products previously or subsequently sold.

USA: T: (800) 334-6259 • OrionFittings.com


Canada: T: (888) 208-8927 • OrionFittings.ca

Latin America: T: (52) 55-4122-0138 • OrionFittings.com

ES-OR-T5-EXT 2633

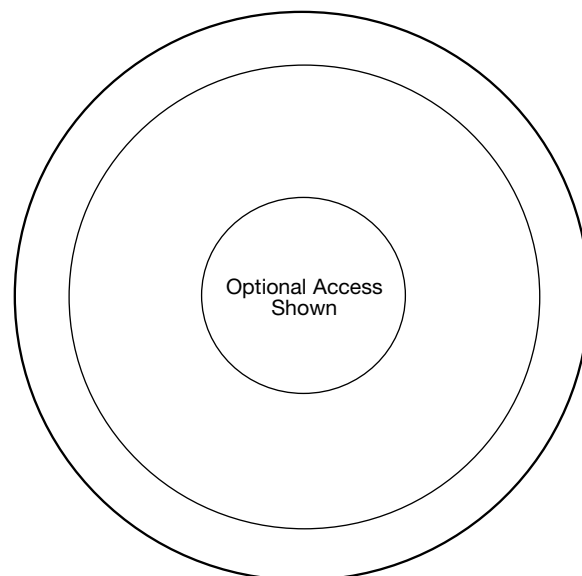

Top View

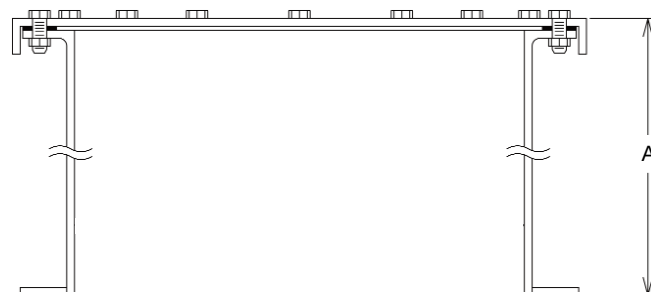

Side View

Note:

Tanks are made to +0.25 in. tolerance.

Tank (Dia.) is +/- 3%.

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Please verify all selections with your local Orion rep - tank products and accessory equipment are non-returnable.

ORION®

A WATTS Brand