

# tekmar® Submittal

## Remote Display Module (RDM) 040



Accessories


**C040**

01/11

Replaces: New

Job \_\_\_\_\_ Designer \_\_\_\_\_ Contact \_\_\_\_\_

The Remote Display Module (RDM) 040 provides the user with a remote interface to any tekmar control that is first generation tN2 capable. It can be used to view and/or adjust the settings on the control that it is connected to. This product also includes an alert relay contact that closes when an error is present on the control that it is connected to.

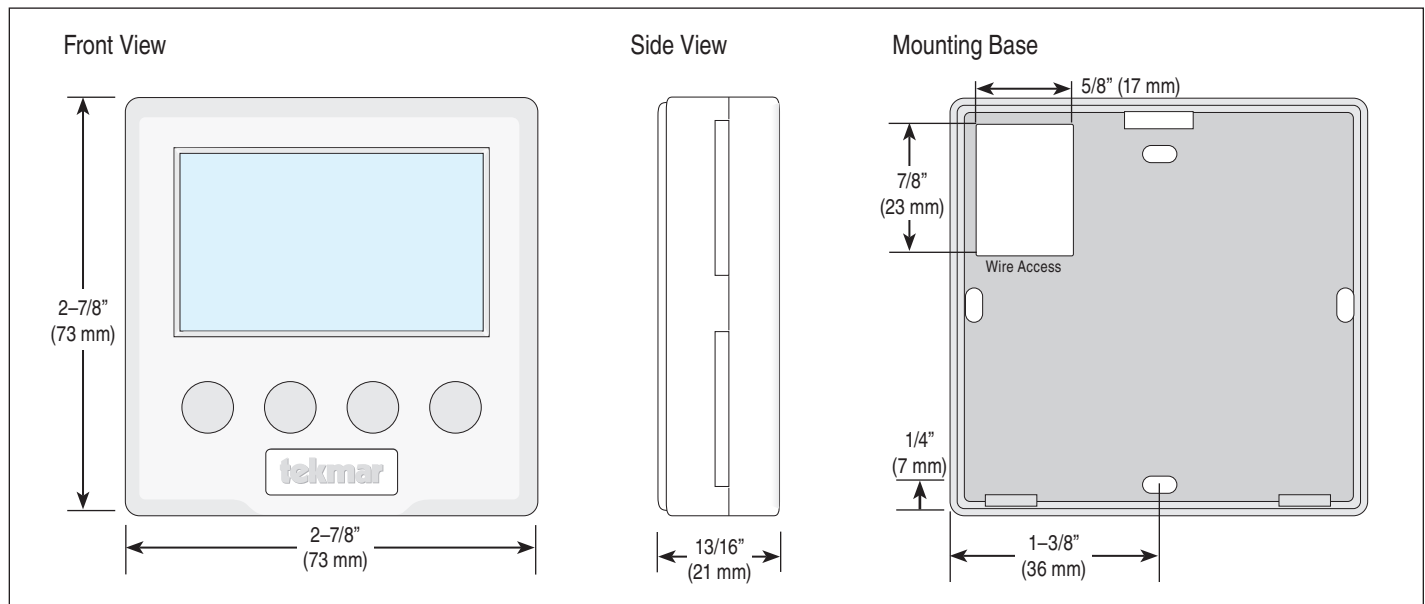

### Specifications

Remote Display Module (RDM) 040	
Literature	D040
Packaged weight	0.3 lb (140 g)
Dimensions	2-7/8" H x 2-7/8" W x 13/16" D (73 x 73 x 21 mm)
Enclosure	White PVC plastic, NEMA type 1
Approvals	CSA C US, meets class B: ICES & FCC Part 15
Ambient conditions	Indoor use only, 32 to 122°F (0 to 50°C), RH < 90% Non-condensing
Power supply	tekmar controls: 362, 363, 664, 665, 667
Relay	24 V (ac or dc) 0.5 A, pilot duty 6 VA
Warranty	Limited 3 Year (See D040 for full warranty)

### Features

- Remote display and control of first generation tN2 controls
- Relay contact for alert indication
- CSA and C US Approved for use in USA and Canada

### SPECIAL REQUIREMENTS

Requires a first generation tN2 control for power and operating.



tekmar Control Systems Ltd., Canada, tekmar Control Systems, Inc., U.S.A. **Head Office: 5100 Silver Star Road, Vernon, B.C. Canada V1B 3K4, 250-545-7749, Fax. 250-545-0650 Web Site: www.tekmarcontrols.com**

