

Engineering Specification

Job Name _____

Contractor _____

Job Location _____

Approval _____

Engineer _____

Contractor's P.O. No. _____

Approval _____

Representative _____

GRD-690

Green Roof Shallow Planter Drain

Specification

Watts GRD-690 epoxy coated cast iron green roof drain with flashing clamp, self-locking ductile iron dome, perforated stainless steel gravel guard with secured solid cover, lift handle and no hub (standard) outlet.


Call customer service if you need assistance with technical details.

Pipe Sizing	
Suffix	Description
2	2"(51) Pipe Size (NH Only)
3	3"(76) Pipe Size
4	4"(102) Pipe Size
5	5"(127) Pipe Size (NH Only)
6	6"(152) Pipe Size
8	8"(203) Pipe Size
10	10"(254) Pipe Size (NH Only)

Outlet Type	
Suffix	Description
NH	No Hub (MJ)
P	Push On
X	Inside Caulk

Options	
Suffix	Description
-13	Galv. Body & Flashing Clamp
-B	Sump Receiver
-D	Underdeck Clamp
-F	Deck Flange/Adj. Extension
-W	Adj. Internal Water Dam

**Deck Opening: 14 1/2"(368)
w/Sump Receiver 18"(457)**

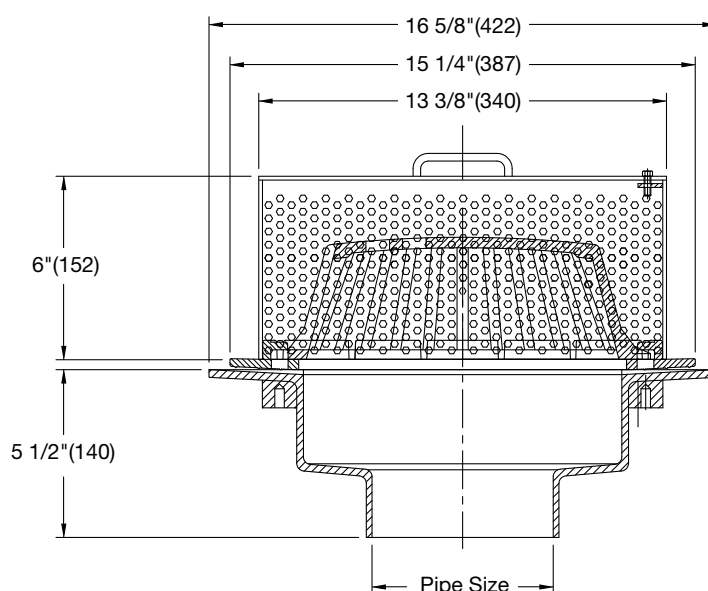

NOTICE

The information contained herein is not intended to replace the full product installation and safety information available or the experience of a trained product installer. You are required to thoroughly read all installation instructions and product safety information before beginning the installation of this product.

Watts product specifications in U.S. customary units and metric are approximate and are provided for reference only. For precise measurements, please contact Watts Technical Service. Watts reserves the right to change or modify product design, construction, specifications, or materials without prior notice and without incurring any obligation to make such changes and modifications on Watts products previously or subsequently sold.



USA: T: (800) 338-2581 • Watts.com

Canada: T: (888) 208-8927 • Watts.ca

Latin America: T: (52) 55-4122-0138 • Watts.com

ES-WD-GRD-690 2506

© 2025 Watts

